

Data Sheet | Item Number: 211-926

Nozzles; Length: 23 mm; For the use of 211-821; halogenated; Cable outer diameter: 10.0 ... 14.0 mm; transparent

<https://www.wago.com/211-926>



Color: ☐ transparent

Technical data	
Suitable	for wire diameter 10 ... 14 mm
Delivery form	Component
Properties	for one 211-821 marker
Printing device	Smart Printer (thermal transfer printer)
Physical data	
Length	23 mm
Mechanical data	
Mounting type	Sliding on conductor
Material data	
Color	transparent
Material	Polyvinyl chloride
Adhesive information	without adhesive
Halogen-free	No
Weight	1.4 g
Fire load	0 MJ
Environmental requirements	
Ambient temperature (storage)	+5 ... +40 °C
Ambient temperature (operation)	-15 ... +70 °C
Relative humidity	40 ... 80 %



Commercial data		
PU (SPU)		200 pcs
Packaging type		Bag
Country of origin		IT
GTIN		4055143381208
Customs tariff number		39269097900

Product Classification		
UNSPSC		39121722
eCl@ss 10.0		27-40-04-01
eCl@ss 9.0		27-40-04-01
ETIM 9.0		EC001530
ETIM 8.0		EC001530
ECCN		NO US CLASSIFICATION

Environmental Product Compliance		
RoHS Compliance Status		Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 211-926	

1 Compatible Products

1.1 Required Accessories

1.1.1 Marking

1.1.1.1 Marker



Item No.: 211-821
Marker; for Smart Printer; for use in nozzles; Length: 23 mm; white


Installation Notes

Application



Slide the marker into the marking sleeve receptacle. Replacing the marker is also possible after the conductor has been terminated.

Application

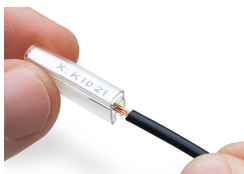

Compress the sleeve and slide it onto the conductor to be marked.