


BR-2/3AG

BR Cylindrical-type Lithium Battery

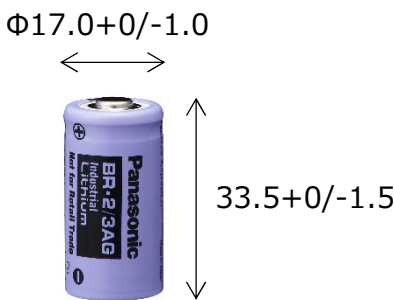

Features & Benefits

- Long-term operating performance
- Suitable for Power supplies for products such as that demand long-term reliability

Applications


Commercial equipment (communication/measurement devices), meters (gas, water, electricity, hot water), memory backup (large FA equipment), automotive electronic components (security alarms), etc.

Specifications


Nominal voltage		3V
Nominal capacity		1,450mAh
Continuous drain		2.5mA
Dimensions*1	Diameter(Max.)	17.0mm
	Height(Max.)	33.5mm
Weight*1		Approx. 13.0g
Operating temperature		-40°C ~ +85°C

*1 Without tabs.

Discharge temperature characteristics

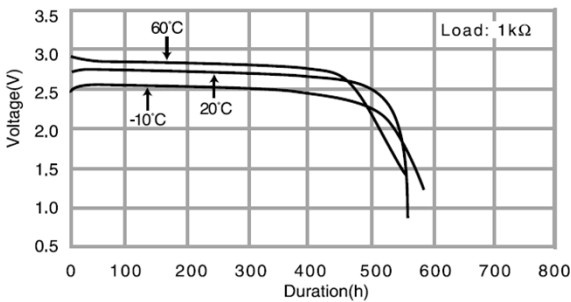

Operating voltage vs. Discharge current (voltage at 50% discharge depth)

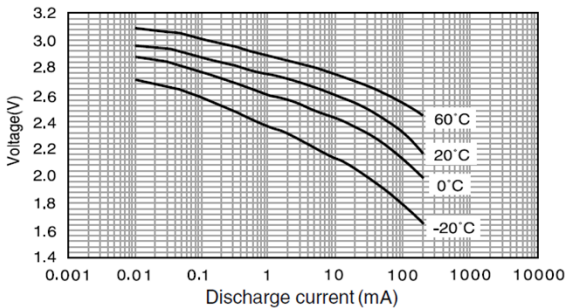

[Panasonic Energy Co., Ltd.](#)

As of July, 2024. Panasonic offers batteries with tabs or lead wires. This data in this document is for descriptive purposes only and is not intended to make or imply any guarantee or warranty. The contents of this product information are subject to change without notice.

