

Housing - HC-B 48-TFL-96/O1STM50S



1460351

<https://www.phoenixcontact.com/us/products/1460351>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



HEAVYCON sleeve housing B48, for single locking latch, height 96 mm, with thread 1x M50, lateral conductor exit

Housing - HC-B 48-TFL-96/O1STM50S



1460351

<https://www.phoenixcontact.com/us/products/1460351>

Commercial Data

Item number	1460351
Packing unit	1 pc
Minimum order quantity	1 pc
Sales Key	B10
Product Key	BF7AAC
Catalog Page	Page 635 (C-2-2017)
GTIN	4046356696579
Weight per Piece (including packing)	635.1 g
Weight per Piece (excluding packing)	628.8 g
Customs tariff number	85389099
Country of origin	DE

Housing - HC-B 48-TFL-96/O1STM50S



1460351

<https://www.phoenixcontact.com/us/products/1460351>

Technical Data

 
Notes

General	For contact inserts HC-B48, DD216, M
---------	--------------------------------------

Product properties

Type	B48
Product type	Housing with locking latch
No. of cable outlets	1
Type of the screw connection	1x M50
Housing type	Sleeve housing
Locking type	for single locking latch
Cable outlet	lateral
Pg screw connection	none

Dimensions

Dimensional drawing	
Width	89 mm
Height	96 mm
Length	131.5 mm

Material specifications

Color	gray
Housing surface material	Powder-coated, gray
Housing material	die-cast aluminum

Ambient conditions

Degree of protection	IP65
Ambient temperature (operation)	-40 °C ... 125 °C

Mechanical properties

Mechanical data

Type of the screw connection	1x M50
Locking type	Pin

Housing - HC-B 48-TFL-96/O1STM50S


1460351

<https://www.phoenixcontact.com/us/products/1460351>



Drawings

Dimensional drawing

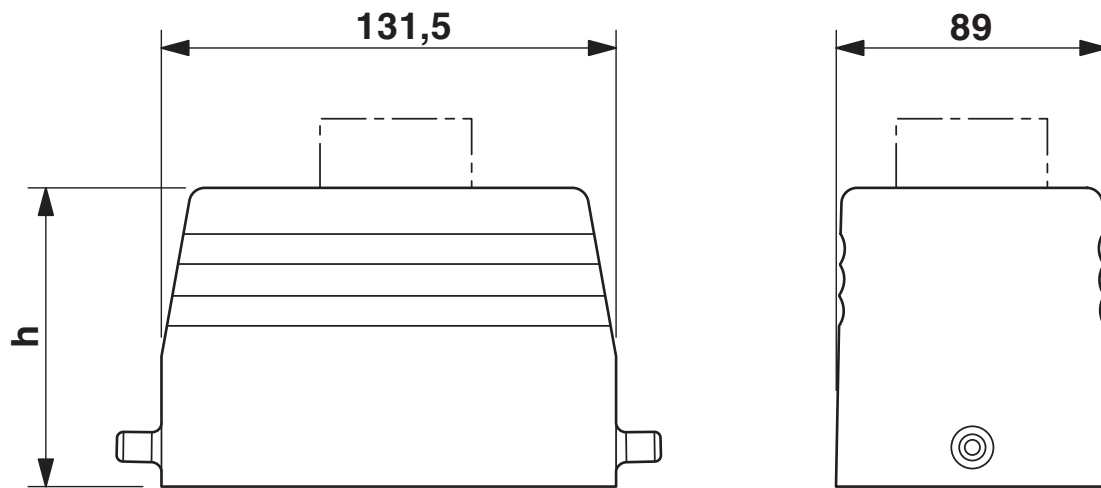

Dimensional drawing

Housing - HC-B 48-TFL-96/O1STM50S



1460351

<https://www.phoenixcontact.com/us/products/1460351>

Classifications

ECLASS

ECLASS-10.0.1	27440202
ECLASS-9.0	27440202
ECLASS-11.0	27440202

ETIM

ETIM 7.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261501
-------------	----------

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Housing - HC-B 48-TFL-96/O1STM50S



1460351

<https://www.phoenixcontact.com/us/products/1460351>

Accessories

Cable gland

Cable gland - G-INS-M50-L68L-PNES-GY - 1411129

<https://www.phoenixcontact.com/us/products/1411129>



Cable gland, cable gland material: PA, external cable diameter 30 mm ... 36 mm, shielding: no, connecting thread: M50 x 1.5, color: silver-gray RAL 7001

Cable gland

Cable gland - G-INS-M50-L68L-PNES-BK - 1411138

<https://www.phoenixcontact.com/us/products/1411138>



Cable gland, cable gland material: PA, external cable diameter 30 mm ... 36 mm, shielding: no, connecting thread: M50 x 1.5, color: jet black RAL 9005

Housing - HC-B 48-TFL-96/O1STM50S

1460351

<https://www.phoenixcontact.com/us/products/1460351>



Cable gland

Cable gland - G-INS-M50-L68N-NNES-S - 1411168

<https://www.phoenixcontact.com/us/products/1411168>



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 27 mm ... 38 mm, shielding: no, connecting thread: M50 x 1.5, color: silver, with O-ring

Cable gland

Cable gland - G-INSEC-M50-L68N-NCRS-S - 1411193

<https://www.phoenixcontact.com/us/products/1411193>



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 24 mm ... 35 mm, shielding: yes, connecting thread: M50 x 1.5, color: silver, with O-ring

Phoenix Contact 2022 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com