

LUMOTAST 75 IP65, signal lamps, rectangular collar, flat bezel,
Solder terminal

DISCONTINUED



Description

The LUMOTAST 75 IP 65 illuminated pushbuttons and signal lamps have been proven for decades and are the most successful monobloc pushbuttons in RAFI history. The versatile collar shapes in the classic design and the familiar connection and labeling concept make the LUMOTAST 75 IP 65 series your reliable component. These pushbuttons and signal lamps offer protection class IP 65 according to DIN.

technical data

> general

Collar shape	rectangular
Operating temperature, min.	-25 °C
Operating temperature, max.	55 °C
Storage temperature, min.	-40 °C
Storage temperature, max.	80 °C
illuminated	Yes
Lamp socket	T4.5
Packaging	Box
Packaging unit	10 pcs.
net weight	7.7 g
Degree of protection, front side, according to DIN EN 60529	IP65
Environment resistance	IEC 60068-2-14 IEC 60068-2-30 IEC 60068-2-33 IEC 60068-2-78
Minimum order quantity (MOQ)	20 pcs.
RoHS compliant	Yes
REACH compliant	Yes
country of origin	HU

direct links

> RAFI eCatalog

> mounting diameters

Outside dimension, length	25 mm
Outside dimension, width	19 mm
Mounting hole	16.2 mm
Mounting depth	33.5 mm
Installation height	10.5 mm

> mechanical data

Fixing	Threaded ring
Solderability	Yes
Terminal on the rear	Solder terminal


> electrical data

Rated current, min.

0.05 A

drawings

Dimensioned drawing

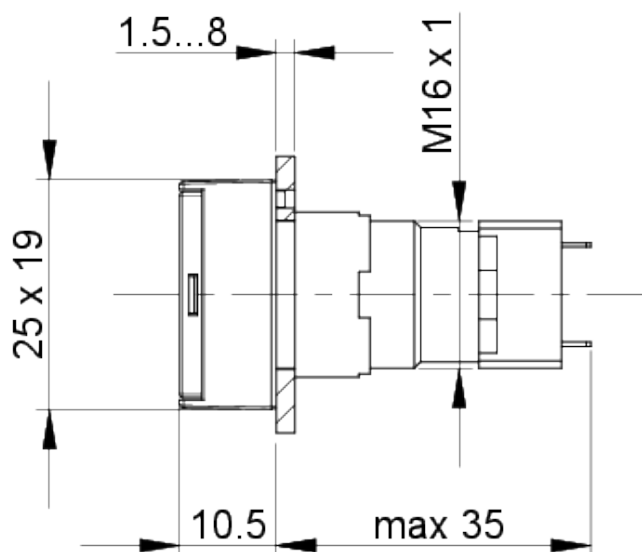

Mounting hole drawing

