

Laser Printer Sheets - General ID Label Sheets (cont.)

Diagram	Part Number	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horizontal Repeat C Inch (mm)	Horizontal Margin E Inch (mm)	Top Margin F Inch (mm)	Labels Per Row	Labels Per Sheet	Labels Per Pkg
Laser-01	LAT-12-747-2.5	Polyester	White	3.000 (76.20)	0.375 (9.53)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	50	2,500
Laser-01	LAT-32-747-1	Polyester	White	3.000 (76.20)	0.900 (22.86)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	20	1,000
Laser-01	LAT-32-759-1	Paper	White	3.000 (76.20)	0.900 (22.86)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	20	1,000
Laser-01	LAT-34-707-1	Polyester	White	3.000 (76.20)	1.437 (36.50)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	12	1,000
Laser-01	LAT-34-747-1	Polyester	White	3.000 (76.20)	1.437 (36.50)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	18	1,000
Laser-01	LAT-34-759-1	Paper	White	3.000 (76.20)	1.437 (36.50)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	18	1,000
Laser-01	LAT-175-124	Paper	White	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-44-707-2.5	Polyester	White	3.600 (91.44)	0.375 (9.53)	-	0.650 (16.51)	0.875 (22.23)	2	40	2,500
Laser-01	LAT-8-712-10	Polyester	Clear	1.000 (25.40)	0.375 (9.53)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	175	10,000
Laser-01	LAT-7-722-10	Polyester	Clear	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-13-712-2.5	Polyester	Clear	1.875 (47.63)	0.833 (21.16)	2.000 (50.80)	0.834 (21.18)	0.310 (7.87)	4	44	2,500
Laser-02	LAT-26-652-10	Polyimide	Amber	0.250 (6.35)	0.250 (6.35)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	26	936	10,000
Laser-02	LAT-1-652-10	Polyimide	Amber	0.300 (7.62)	0.250 (6.35)	0.700 (17.78)	0.875 (22.23)	0.450 (11.43)	22	836	10,000
Laser-01	LAT-2-652-10	Polyimide	Amber	0.375 (9.53)	0.375 (9.53)	0.500 (12.70)	0.875 (22.23)	0.313 (7.95)	16	400	10,000
Laser-01	LAT-25-652-10	Polyimide	Amber	0.500 (12.70)	0.437 (11.10)	0.600 (15.24)	0.875 (22.23)	0.400 (10.16)	13	286	10,000
Laser-01	LAT-3-652-10	Polyimide	Amber	0.650 (16.51)	0.250 (6.35)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	380	10,000
Laser-01	LAT-29-652-10	Polyimide	Amber	0.650 (16.51)	0.200 (5.08)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	480	10,000
Laser-01	LAT-4-652-10	Polyimide	Amber	0.800 (20.32)	0.250 (6.35)	1.000 (25.40)	0.875 (22.23)	0.350 (8.89)	8	304	10,000
Laser-01	LAT-5-652-10	Polyimide	Amber	0.800 (20.32)	0.500 (12.70)	1.000 (25.40)	0.875 (22.23)	0.350 (8.89)	8	152	10,000
Laser-01	LAT-6-652-10	Polyimide	Amber	1.000 (25.40)	0.250 (6.35)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	266	10,000
Laser-01	LAT-8-652-10	Polyimide	Amber	1.000 (25.40)	0.375 (9.53)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	175	10,000
Laser-01	LAT-7-652-10	Polyimide	Amber	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-9-652-10	Polyimide	Amber	1.500 (38.10)	0.250 (6.35)	1.600 (40.64)	0.875 (22.23)	0.350 (8.89)	5	190	10,000
Laser-01	LAT-10-652-10	Polyimide	Amber	1.875 (47.63)	0.250 (6.35)	2.000 (50.80)	0.875 (22.23)	0.314 (7.98)	4	156	10,000
Laser-01	LAT-12-652-2.5	Polyimide	Amber	3.000 (76.20)	0.375 (9.53)	3.200 (81.28)	0.875 (22.23)	1.150 (29.21)	2	50	2,500
Laser-01	LAT-7-773-10	Metallized Polyester	Silver	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-20-773-2.5	Metallized Polyester	Silver	1.500 (38.10)	0.750 (19.05)	1.600 (40.64)	0.875 (22.23)	0.250 (6.35)	5	60	2,500
Laser-01	LAT-21-773-1	Metallized Polyester	Silver	2.500 (63.50)	1.000 (25.40)	2.600 (66.04)	0.875 (22.23)	0.300 (7.62)	3	27	1,000
Laser-01	LAT-29-747-10-YL	Polyester	Yellow	0.650 (16.51)	0.200 (5.08)	0.800 (20.32)	0.875 (22.23)	0.325 (8.26)	10	480	10,000
Laser-01	LAT-7-747-10-YL	Polyester	Yellow	1.000 (25.40)	0.500 (12.70)	1.100 (27.94)	0.875 (22.23)	0.450 (11.43)	7	133	10,000
Laser-01	LAT-13-747-2.5-YL	Polyester	Yellow	1.875 (47.63)	0.833 (21.16)	2.000 (50.80)	0.834 (21.18)	0.310 (7.87)	4	44	2,500
Laser-01	LAT-21-747-1-YL	Polyester	Yellow	2.500 (63.50)	1.000 (25.40)	2.600 (66.04)	0.875 (22.23)	0.300 (7.62)	3	27	1,000
Laser-01	LAT-175-124-YL	Paper	Yellow	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-BL	Paper	Blue	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-PUR	Paper	Purple	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-BR	Paper	Brown	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-GR	Paper	Green	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-GY	Paper	Gray	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-OR	Paper	Orange	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380
Laser-01	LAT-175-124-RD	Paper	Red	3.062 (77.77)	0.500 (12.70)	0.500 (12.70)	0.938 (23.83)	1.118 (30.18)	2	38	380

Laser Printer Sheets - Permashield Label Sheets

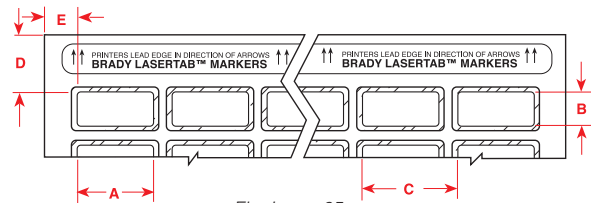


Fig. Laser-05

Diagram	Part Number	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horizontal Repeat C Inch (mm)	Horizontal Margin E Inch (mm)	Top Margin F Inch (mm)	Labels Per Row	Labels Per Sheet	Labels Per Pkg
Laser-05	LAT-23-747-2.5	Polyester	White	1.000 (25.40)	0.500 (12.70)	1.350 (34.29)	1.000 (25.40)	0.275 (6.99)	6	60	2,500
Laser-05	LAT-24-747-1	Polyester	White	1.750 (44.45)	1.000 (25.40)	2.200 (55.88)	1.000 (25.40)	1.175 (29.85)	3	21	1,000
Laser-05	LAT-23-773-2.5	Metallized Polyester	Silver	1.000 (25.40)	0.500 (12.70)	1.350 (34.29)	1.000 (25.40)	0.275 (6.99)	6	60	2,500
Laser-05	LAT-24-773-1	Metallized Polyester	Silver	1.750 (44.45)	1.000 (25.40)	2.200 (55.88)	1.000 (25.40)	1.175 (29.85)	3	21	1,000

Full Material Properties on page 237.