

- Connectors
- > Customer specific solutions

> D SUB

> D SUB cover

> D SUB accessories

> DVI

> Centronics

> IDC

> Modular

> USB

> IEEE 1394

> Switches

> Power supply

> DIN 41612

> DIN 41617

> Mini DIN

> IC Socket

> **Pin and female header**

> Jumper

> Connector sleeves

> Solder terminals


> Test terminals

> Terminal Blocks

> Memory Card connectors

> FFC / FPC connectors

> Micro-Miniature
- Thermal management
- Cable assembly

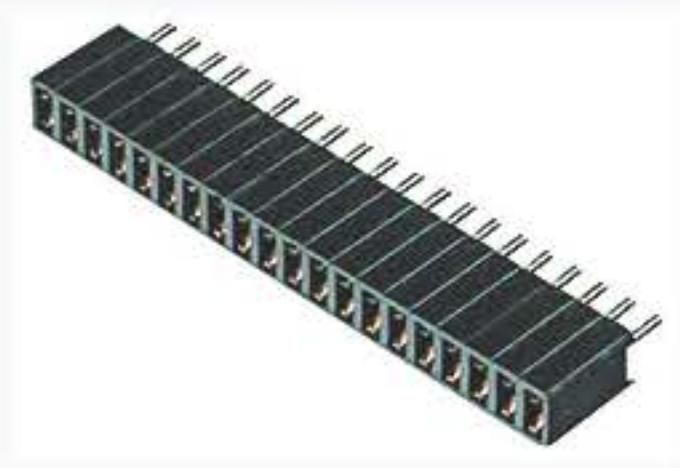

Pin and female header

AWL254-DG-G04A
female-header 03pins THT 1,27mm 1A single row 2,40mm straight Au

Article number: ABL127 E G G 03 D

product group: pin-&female-header

style: female-header

contact type: THT

pin count: 3

spacing in mm: 1,27

current rating: 1A

version: single row

contact length: 2,40mm

contact direction: straight

plating: Au

contact machining: stamped contacts

packaging: tray

process: THT

insulator: Nylon6T UL94V-0

: AWL254-DG-G04A

: #NV

» PDF download «

