




- Home
- Products
- Online Catalog
- Request Quote
- Order Online
- Check Stock
- Request Print Catalog
- Request Samples
- Engineering Data
- Distributors
- Capabilities Brochure

CALL NOW:  
203 888-2133



Home > 8mm Hex Male-Female Standoffs

8MM HEX MALE-FEMALE STANDOFFS

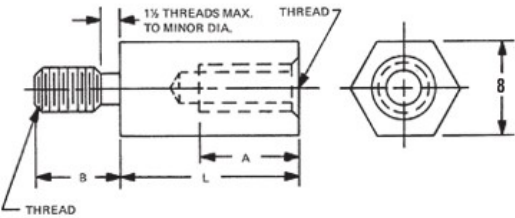

| MINIMUM THREAD DEPTH "A" |                 |     |     |     |     |     |     |     |     |      |      |      |      |
|--------------------------|-----------------|-----|-----|-----|-----|-----|-----|-----|-----|------|------|------|------|
| Thread                   | Body Length "L" |     |     |     |     |     |     |     |     |      |      |      |      |
|                          | 5               | 6   | 7   | 8   | 9   | 10  | 11  | 12  | 13  | 14   | 15   | 16   | 17   |
| M3x0.5                   | 1.8             | 2.8 | 3.8 | 4.8 | 5.8 |     |     |     |     |      |      |      |      |
| M3.5x0.6                 | 1.5             | 2.5 | 3.5 | 4.5 | 5.5 | 6.5 | 7.5 | 8.5 | 9.5 |      |      |      |      |
| M4x0.7                   | 1.1             | 2.1 | 3.1 | 4.1 | 5.1 | 6.1 | 7.1 | 8.1 | 9.1 | 10.1 | 11.0 |      |      |
| M5x0.8                   | .6              | 1.6 | 2.6 | 3.6 | 4.6 | 5.6 | 6.6 | 7.6 | 8.6 | 9.6  | 10.6 | 11.6 | 12.6 |

In short lengths, "A" will be tapped to maximum depth.  
For non-standard parts, [contact us](#).

HomePreviousNext

Related ASE

Ordering Code

|        |        |          |        |
|--------|--------|----------|--------|
| xxxxx  | xxxx   | xx       | x      |
|        |        |          |        |
| Length | Thread | Material | Finish |

PART: M2189 4007 N

Red ?'s show missing selections. [Help](#)

- [Material Specifications](#)
- [Ordering non-standard items](#)
- [Download a Drawing](#)

Qty1 \*

Qty2

Add to Cart

Qty3

Length \*

| Select                           | Part No. | Length |
|----------------------------------|----------|--------|
| <input type="radio"/>            | M2180    | 5      |
| <input type="radio"/>            | M2181    | 6      |
| <input type="radio"/>            | M2182    | 7      |
| <input type="radio"/>            | M2183    | 8      |
| <input type="radio"/>            | M2184    | 9      |
| <input type="radio"/>            | M2185    | 10     |
| <input type="radio"/>            | M2186    | 11     |
| <input type="radio"/>            | M2187    | 12     |
| <input type="radio"/>            | M2188    | 13     |
| <input checked="" type="radio"/> | M2189    | 14     |
| <input type="radio"/>            | M2190    | 15     |

Thread \*

| Select                           | Code | Thread   | A    | B    |
|----------------------------------|------|----------|------|------|
| <input type="radio"/>            | 3005 | M3x0.5   | 6.4  | 4.76 |
| <input type="radio"/>            | 3506 | M3.5x0.6 | 9.5  | 6.35 |
| <input checked="" type="radio"/> | 4007 | M4x0.7   | 11.1 | 9.53 |
| <input type="radio"/>            | 5008 | M5x0.8   | 12.7 | 9.53 |

Material \*

| Select                           | Code | Material        | RoHS |
|----------------------------------|------|-----------------|------|
| <input type="radio"/>            | AL   | Aluminum        | YES  |
| <input type="radio"/>            | B    | Brass           | YES  |
| <input type="radio"/>            | SS   | Stainless Steel | YES  |
| <input type="radio"/>            | S    | Steel           | YES  |
| <input checked="" type="radio"/> | N    | Nylon           | YES  |

Finish \*

|                                  |                                  |
|----------------------------------|----------------------------------|
| <input checked="" type="radio"/> | Plain Finish                     |
| <input type="radio"/>            | 1-Cad clear chromate/commercial* |
| <input type="radio"/>            | 2-Cad clear chromate*            |
| <input type="radio"/>            | 3-Cad yellow chromate*           |
| <input type="radio"/>            | 4-Chrome over nickel             |
| <input type="radio"/>            | 5-Nickel                         |
| <input type="radio"/>            | 6-Gold iridite                   |
| <input type="radio"/>            | 7-Clear iridite                  |
| <input type="radio"/>            | 9-Alodine 1200*                  |
| <input type="radio"/>            | 10-Bright chrome                 |
| <input type="radio"/>            | 11-Satin chrome                  |
| <input type="radio"/>            | 12-Zinc                          |