


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2017/4/12

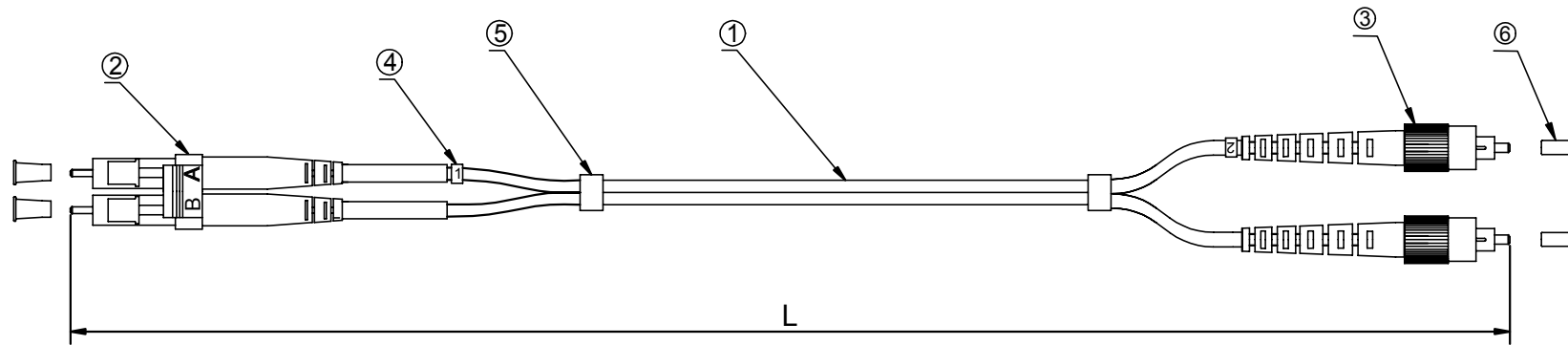

 
PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
914S-2-5-00100	671-462-A	1000±100	Yellow
914S-2-5-00200	671-462-B	2000±100	Yellow
914S-2-5-00300	671-462-C	3000±100	Yellow
914S-2-5-00500	671-462-D	5000±100	Yellow
914S-2-5-00700	671-462-E	7000±100	Yellow
914S-2-5-01000	671-462-F	10000±100	Yellow
914S-2-5-01500	671-462-G	15000±100	Yellow
914S-2-5-02000	671-462-H	20000±100	Yellow
914S-2-5-02500	671-462-I	25000±100	Yellow

NOTES:

Insertion loss < 0.3 dB

Return loss > 50 dB

6	Dust Cover
5	Shrinkage Tube
4	$\frac{1}{2}$ Code
3	FC SM Connector (Metal housing Blue boot)
2	LC SM Duplex Connector (Blue housing White boot)
1	2.0mm,Duplex,SM-9/125 G652D, PVC, Optical Fiber Cable(Yellow)
No.	Description

CnC Tech, LLC Industrial Cable and Connector Technology					
		TITLE	Patch Cord, LC-FC,SM-9/125 G652D, Duplex, PVC, yellow, 2.0mm, xxM		
UNIT	mm	P/N		DRAWN BY	
unless otherwise stated mm Tolerances XXX.XX ±0.3 ±2° XX.XX ±0.2 X.XX ±0.1		Customer P/N	914S-2-5-0xxxx	CHECK BY	
SIZE	A4	SCALE	Free	PAGE	1/1
		APPROVAL BY			