


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	NOTES
1	50-00024	Connector, dc plug, 5.5x2.1xL23 mm, molding style, spring contacts, LF	1	
2	30-00003	Wire, 2C BC, 24 AWG, UL2468, 300V, 80C, 3.6 mm, VW-1, PVC	1	
3	24-00003	Overmold, PVC, black	1	

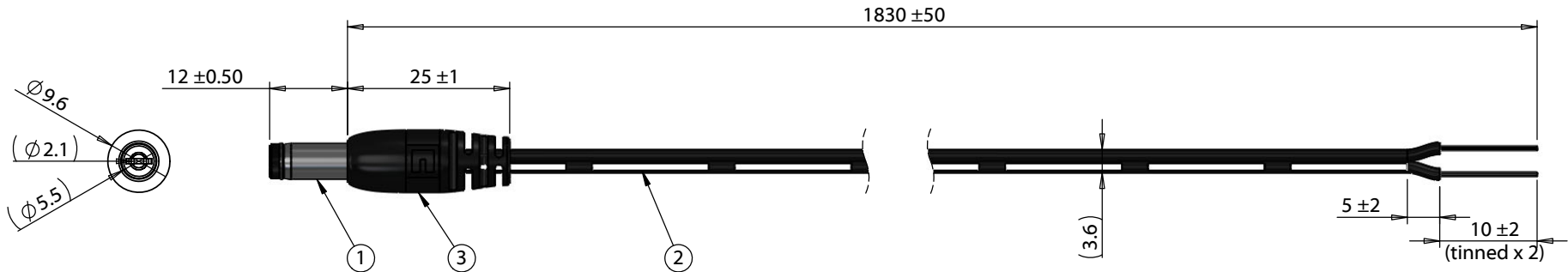

Ratings

Maximum Operating Voltage: 48 V
Maximum Operating Current: 4.5 A

Operating Temperature Range

-25 ~ 80 °C, relative humidity of 85% or less

Notes:

Functionally equivalent components may be substituted

Wiring diagram	
50-00024	Wire Color
Center	Black with stripe
Sleeve	Black

Revision:	Date:	Description:	Prepared:	Notes: RoHS compliant	TENSILITY tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com		
A	6/28/2012	Initial release	Verified:			Function test: no open, no short circuit, no intermittent	
A1	02/04/26	Corrected current rating	Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Description: Cable, 1830 mm, 5.5x2.1x12 mm 50-00024 dc plug to stripped tinned, 24 AWG, 30-00003 wire	Size: A	Part number: 10-01062	
					Scale: 1:2		Sheet 1 of 1

5

4

3

2

1