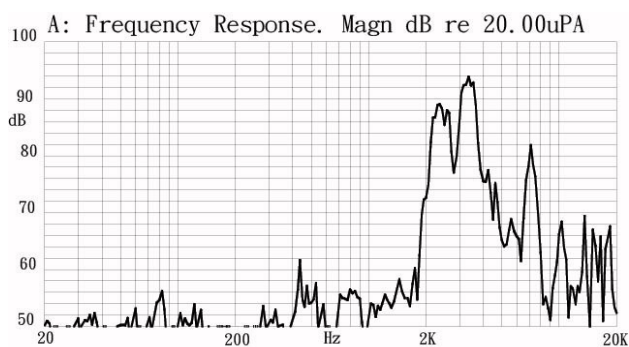


You are here: [Home](#) ▶ [Piezo Buzzer](#) ▶ [Piezo Sounder](#) ▶ KPEG1600NC

KPEG1600NC

[Print](#)


Additional Info

Rated Frequency (Hz):	3000+/-30%
Rated Voltage (Vp-p / VDC):	Max 15
Current Consumption (mA):	Max 30 @90Vpp, Sine Wave, 3.5KHz
Sound Pressure Level (dB):	Min 95dB@100cm/90Vpp, Sine Wave, 3.5KHz
Operating Temperature (°C):	-20 ~ + 60
Storage Temperature (°C):	-30 ~ + 70
Dimension (mm):	Φ54.5x23.0

 **Like** [Sign Up](#) to see what your friends like.

Tagged under [Piezo Sounder Transducer 150Vpp 35KHz](#)

More in this category: [KPEG1600NCB »](#)

[back to top](#)

