



**Part Number :** [39036154](#)


**Product Description :** 2.36mm Diameter Standard .093" Pin and Socket Receptacle Housing with Positive Latch, UL 94V-2, without Panel Mount, 15 Circuits

**Series Number :** 3191

**Status :** Active

**Product Category :** Connector Housings

**Engineering Part Number :** 3191-15R1

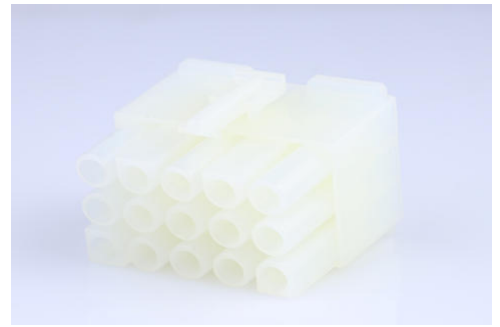

---

## Documents and Resources

### Drawings

[039036154\\_sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

### Specifications

[SPK-3191-001-001.pdf](#)


[PS-3191-001-001.pdf](#)

[PS-3191-003-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### Substances of Interest

- PFAS

### EU RoHS Certificate of Compliance

### Additional Product Compliance Information

---

## Part Details

### General

Status	Active
Category	Connector Housings
Series	3191
Description	2.36mm Diameter Standard .093" Pin and Socket Receptacle Housing with Positive Latch, UL 94V-2, without Panel Mount, 15 Circuits
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	Polarized to Mating Part
Product Name	Standard .093"
UPC	800753756588

### Agency

CSA	LR19980
UL	E29179

### Physical

Circuits Detail	3x5
Circuits (maximum)	15

Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	10808.500/mg
Number of Rows	3
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	6.70mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
2.36mm Diameter Standard .093" Pin and Socket Plug Housing with Positive Latch, UL 94V-2, Panel Mount, 15 Circuits	<a href="#"><u>39036150</u></a>
2.36mm Diameter Standard .093" Pin and Socket Plug Housing with Positive Latch, UL 94V-2, without Panel Mount, 15 Circuits	<a href="#"><u>39036152</u></a>
Standard .093" Pin and Socket Vertical Headers	<a href="#"><u>5219</u></a>

### Use with Part(s)

Description	Part Number
Standard .093" Pin and Socket Female Crimp Terminals	<a href="#"><u>1189</u></a>
Standard .093" Pin and Socket Female Crimp Terminals	<a href="#"><u>1381</u></a>

Standard .093" Pin and Socket Female Crimp Terminal	<u>4550</u>
Standard .093" Pin and Socket Male Crimp Terminals	<u>1190</u>
Standard .093" Pin and Socket Male Crimp Terminals	<u>1380</u>
Standard .093" Pin and Socket Male Crimp Terminal	<u>1434</u>
Standard .093" Pin and Socket Male Crimp Grounding Terminals	<u>1973</u>
2.36mm Diameter, Standard .093" Pin and Socket Male Crimp Terminals	<u>42138</u>

---

This document was generated on May 25, 2026