

Get **10% OFF** On Your First Purchase



Search

\$USD



LOGIN/SIGN UP

HOME COMMUNITY WIKI BLOG

WISH LIST (0)

Home / Metal DC Geared Motor w/Encoder - 6V 210RPM 10Kg.cm



Metal DC Geared Motor w/Encoder - 6V 210RPM 10Kg.cm

SKU:FIT0521

Brand:Other

Reward Points:20

Tags:

FIT0521

dc motor

gear motor

hall encoder

dc gear motor

Related Categories

All Products

Motors & Actuators & Drivers

DC Motors

Sensors & Modules



ADD TO WISHLIST

In Stock

Price in reward points: 1990

Qty

1



BUY IT NOW

ADD TO CART

INTRODUCTION

DOCUMENT

TUTORIAL

BACK TO TOP



Frequently Bought Together



Metal DC Geared Motor w/Encoder - 6V 210RPM 10Kg.cm

+



2x2A DC Motor Shield for Arduino

+



DFRduino UNO R3 - Arduino Compatible

+



Gravity IO Expansion Shield for Arduino V7.1


You have choosen:0

Total amount:

BUY NOW


INTRODUCTION

This is a metal geared DC motor w/Encoder. It is a 6V motor with a 34:1 metal gearbox and an integrated quadrature encoder that provides a resolution of 11 counts per revolution of the motor shaft, which corresponds to 341.2 counts per revolution of the gearbox's output shaft.

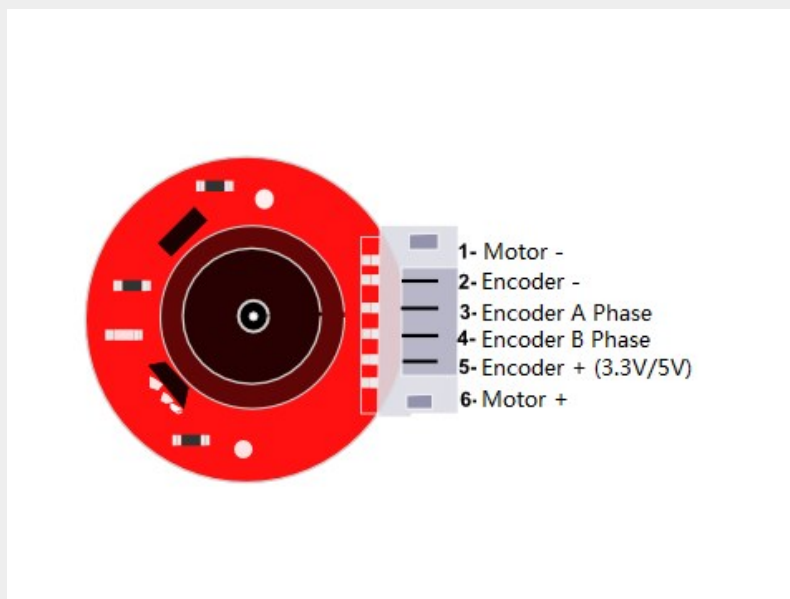

Pinmap

These units have an 8 mm length, 4 mm-diameter D-shaped output shaft. This motor is intended for use at 6V, though the motor can begin rotating at voltages as low as 1V. This motor is an ideal option for your mobile robot project.

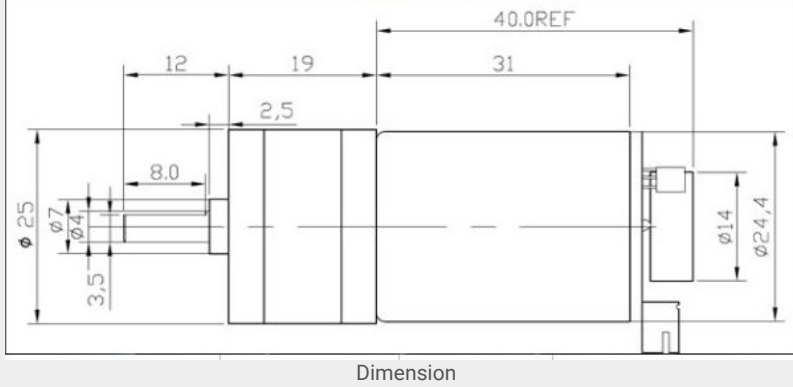

Dimension

SPECIFICATION

Motor Rated Voltage: 6V
Encoder Rated Voltage: 3.3 / 5V
Reducer Reduction Ratio: 1: 34
No load Speed: 210RPM@0.13A
Maximum Efficiency Point: load 2.0kg·cm/170RPM/2.0W/0.6A
Maximum Power point: Load 5.2kg·cm/110RPM/3.1W/1.1A
Stall Torque: 10kg·cm
Stall Current: 3.2A
Hall Resolution: Hall Resolution 11x Precision Reduction Ratio 34.02 = 341.2PPR
Dimension: 52 * ϕ 24.4 mm / 2.05 * ϕ 0.96inches
Weight: 96g

SHIPPING LIST

Metal DC Geared Motor w/Encoder - 6V 210RPM 10Kg.cm x1
JST 6-Pin cable x1

REVIEW

0 Comments

DFRobot

1 Login

Recommend

Share

Sort by Best

 Start the discussion...

Be the first to comment.

ALSO ON DFRobot

Gravity: Analog Spear Tip pH Sensor / Meter Kit (for Soil and Food Applications)

6 comments · 4 months ago

DFRobot Support — No, this sensor has a life spam and it is a laboratory sensor which is not suitable for prolonged online testing.

ESP32 Projects: Mail Alarm

5 comments · a month ago

Tiobel — Yes, but the Wifi.h library that I'm using is not supported in the ESP8266. You will need to replace it for ESP8266WiFi.h. Check some of the examples in the Arduino ...

Micro:bit Light(Mood Lamp)

3 comments · 2 months ago

DFRobot Support — This is a new product that we would release it later. We are now still doing some preparation.

Top 5 Best Selling Sensor Sales

1 comment · 2 months ago

Crazy Couple — Nice

 Subscribe  Add Disqus to your site  Privacy

DISQUS

Recently Viewed Items and Featured Recommendations



LattePanda - A Powerful Windows 10 Mini PC 4GB/64GB (Unactivated)



LattePanda - A Powerful Windows 10 Mini PC 2GB/32GB



Acrylic Case for LattePanda - Cooling Fan Compatible!



Aluminum Heatsink Cooling Fan for LattePanda

Sign up for exclusive offers!

Your email address



Like us on



INFORMATION

[About Us](#)
[Warranty](#)
[Privacy Policy](#)
[Shipping](#)
[Payment](#)
[FAQ](#)

CUSTOMER SERVICE

[DFRobot Distributors](#)
[Contact us](#)
[Site Map](#)

MY ACCOUNT

[Affiliates](#)
[Specials](#)

Powered By DFRobot © 2008- 2018