

Ledlink Optics, Inc
Taiwan(HQ):
15F, No.655,Bannan Rd.,
Chung - Ho Dist, New Taipei City,
Taiwan 235
T.+886-2-8227-6126

Ledlink Optics(Dong Guan) Co., Ltd
Dong-Guan(Factory):
No.5, TianKeng Industrial District
HengLi Town, DongGuan City
GuangDong Province China 523478
T.+86-769-8897-7888

Ledlink Optics(Yang Zhou) Co., Ltd
Yang-Zhou(Factory):
No.180,LinJiang Road,Yangzhou
City,Jiangsu Province,China
T.+86-0514-8510-9000

service@ledlink-optics.com
www.ledlink- optics.com



LL01CR-APM80150L02



FWHM 80x150°
DxWxH(mm) 18 x 12.5 x 6.95
Cree XP-E2/G2/XT-E/XB-D/ MHB/
XPL-HD/XHP35-HD(HI)
LGInnotek H35C1
Lumileds Rebel/Luxeon T
Osram Oslon SSL80/Square/Duris S8
Samsung LH351A/B/Z
Seoul MJT 2525/3030/4040/5050/
Z8Y15/19

LL01CR-AEC30140L02



FWHM 30x140°
DxWxH(mm) 22 x 19 x 10
Cree XML-2

LL01CR-FT60135L02



FWHM 60x135°
DxWxH(mm) 18 x 9.3 x 5.9
Cree XP-E2(G2)/XB-D/XHP35-HI
LGInnotek H35A/H35C1
Lumileds Rebel(ES)/Luxeon A(T)
Nichia NVS19B
Samsung LH351A/B/Z
Osram Oslon SSL80/Square
Seoul MJT2525/3030/4040/5050

LL01CR-AU85135L02



FWHM 85x135°
DxWxH(mm) 18 x 10.2 x 6.1
Cree XP-E2/G2/XB-D/XHP35-HI
LGInnotek H35A/H35C1
Lumileds Rebel (ES)/Luxeon A(T)
Nichia NVS19B/757D
Osram Oslon SSL 80/150/Square
Samsung LH351A/B/Z
Seoul MJT2525/3030/4040/Z8Y15/19

LL01CR-XW70140L02



FWHM 70x140°
DxWxH(mm) 32 x 17.6 x 9.8
Cree XPL-HD/MHB/XHP50(70)
LGInnotek H35C1
Lumileds Luxeon M
Osram Ostar/Duris S8

LL01CR-PB70140L02



FWHM 70x140°
DxWxH(mm) 22.4 x 11.4 x 6.9
Cree XP-E2(G2)/XT-E/XB-D
XPL-HD/XHP35-HD(HI)
LGInnotek H35A/H35C1
Nichia NVS19B
Osram Oslon Square
Samsung LH351A/B/Z
Seoul MJT2525/3030/4040/
Z8Y15/19

LL01CR-BAJ85135L02



FWHM 85x135°
DxWxH(mm) 18 x 12.5 x 6.1
Cree XP-E2/ G2/XHP35- HI
LGInnotek H35C1
Lumileds Luxeon T
Nichia NVS19B/757D
Samsung LH351A/B/Z
Seoul MJT2525/3030/4040

LL01CR-OG85150L02




FWHM 85x150°
DxWxH(mm) 18 x 8.95 x 6.2
Cree XP-E/XP-G2/XB-D
LGInnotek Luxeon Rebel/ES
Nichia NVS19B
Osram Oslon Square
Samsung LH351A/B/Z

LL01CR-OW70130L02



FWHM 70x130°
DxWxH(mm) 17.4 x 12.75 x 7.2
Cree XP-E2(G2)/XPL-HD/XT-E/
XB-D/XHP35-HD(HI)
LGInnotek H35A/H35C1
Lumileds Rebel/Luxeon T
Samsung LH351A/B/Z
Osram Oslon SSL80/150/Square/
Oslon Ostar
Nichia NVS19B/757D
Seoul MJT2525/3030/4040/5050/
Z8Y15/19

LL01CR-KM6090L02

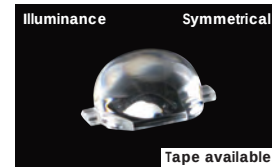

FWHM 60x90°
DxWxH(mm) 17.55 x 11.6 x 8.6
Cree XP-E2(G2)/XHP35- HI
LGInnotek H35A/H35C1
Lumileds Rebel (ES)/Luxeon A
Nichia NVS19B/757D
Samsung LH351A/B/Z
Osram Oslon SSL80/Square/Duris S8
Seoul MJT 2525/3030/4040/5050/
Z8Y15/19

LL01LU-AGV80150L02




FWHM 80x150°
DxWxH(mm) 32 x 18.5 x 9.5
Cree XPL-HD/XML-2/XHP50(70)
Lumileds Luxeon M/MZ
Nichia NS9x383
Osram Duris S8/Ostar

LL01OS-AU60140L02




FWHM 60x140°
DxWxH(mm) 16 x 8.8 x 5.3
Cree XP-E2(G2)/XPL-HD
XHP35-HI
LGInnotek H35C1
Lumileds Luxeon A(T)
Nichia NVS19B/757D
Osram Oslon SSL80
Samsung LH351A/B/Z
Seoul MJT2525/Z8Y15/19

LL01ED-AU70120L02

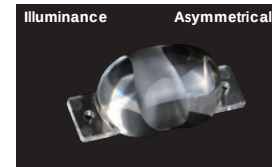

FWHM 70x120°
DxWxH(mm) 94 x 42 x 28.4
Bridgelux Vero10/18/29
Cree CXA25xx
Lexar PB 20/30/40

LL01LU-AIK45135L02

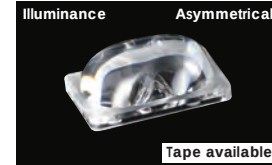

FWHM 45x135°
DxWxH(mm) 18 x 12.5 x 7.05
Cree XP-G2/XPL-HD/XHP35-HD(HI)
LGInnotek H35C1
Lumileds Rebel (ES)/Luxeon T
Nichia NVS19B
Samsung LH351A/B/Z
Seoul MJT2525/3030/4040/Z8Y15/19

LL01SX-ADD60135L02




FWHM 60x135°
DxWxH(mm) 25.7 x 16.3 x 11.4
Cree MHB
Samsung LH934A

LL01LU-UQ70140L02



FWHM 70x140°
DxWxH(mm) 18 x 11 x 6.6
Cree XP-E2(G2)/XT-E/XB-D
XPL-HD/XHP35-HD(HI)
LGInnotek H35C1
Lumileds Rebel/Rebel ES
Nichia NVS19B/757D
Osram Duris S8
Samsung LH351A/B/Z
Seoul MJT4040/5050/Z8Y15/19

LL01LU-AEV50150L02

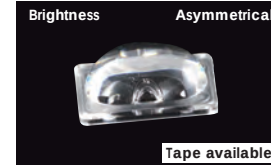

FWHM 50x150°
DxWxH(mm) 18 x 12.5 x 6.3
Cree XP-G/XHP35-HI
Lumileds Rebel ES/Luxeon A(T)
Nichia NVS19B
Seoul MJT4040

LL01ZZ-AGX45155L02



FWHM 45x155°
DxWxH(mm) 18 x 12.5 x 7
Cree XP-E2(G2)/XHP35- HI
LGInnotek H35A/H35C1
Lumileds Rebel(ES)/Luxeon A(T)
Samsung LH351A/B/Z
Seoul MJT 2525/3030/Z8Y15/19



Street Lighting

LED made easy


Ver 16.05

LL04CR-CFN35155L02




FWHM 35x155°
DxWxH(mm) 50 x 50
Cree XP-E2/XP-G2/XPL-HD
XHP35HD
Lumileds Luxeon T

LL04CR-BXJ90L02

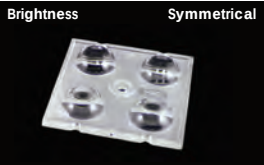


FWHM 90°
DxWxH(mm) 50 x 50 x 7.3
Cree XP-E2/XPL-HD/MHB
Lumileds Luxeon T
Nichia 757D
Osram Oslon Square
Seoul Z5M1/M2

LL04CR-CGM85135L02

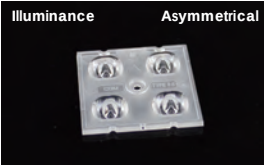


FWHM 85x155°
DxWxH(mm) 50 x 50
Cree XP-E2(G2)/XPL-HD/XT-E

LL04CR-CFN60155L02

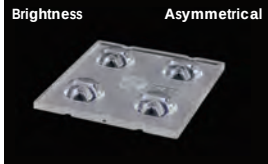

FWHM 60x155°
DxWxH(mm) 50 x 50
Cree XP-E2/XP-G2/XPL-HD
XHP35HD
Lumileds Luxeon T
Seoul Z5M1/M2

LL04CR-BXJ45155L02

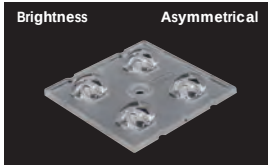

FWHM 45x155°
DxWxH(mm) 50 x 50 x 6.95
Cree XP-E 2/XP-G2/XPL-HI
LGInnotek H35A/H35C1
Lumileds Rebel(ES)/Luxeon A(T)
Samsung LH351A/ B/ Z
Nichia NVS19B
Seoul Z5M1/M2/MJT2525/
3030/4040

LL12ZZ-CRC45145L19




FWHM 45x145°
DxWxH(mm) 50 x 50 x 50
Cree XPE2/ XPG2
Edison 3030
Lumileds Luxeon3030
Nichia 757D
Osram Oslon square

LL04CR-BXJ60L02



FWHM 60°
DxWxH(mm) 50 x 50 x 7.3
Cree XP-E2/XPL-HD/MHB
Lumileds Luxeon T
Seoul Z5M1/M2
Osram Oslon Square

LL04CR-BXJ80150L02

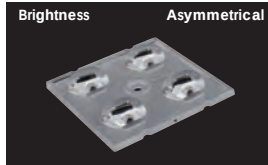

FWHM 80x150°
DxWxH(mm) 50 x 50 x 7.05
Cree XP-E2/XP-G2/XPL-HD/
XT-E/XB-D
Lumileds Rebel/Luxeon T
Osram Oslon SSL80/Square/Duris S8
Samsung LH351A/B/Z
Nichia NVS19B
Seoul MJT2525/3030/4040/5050

LL12ZZ-CRC45155L19




FWHM 45x155°
DxWxH(mm) 50 x 50 x 50
Cree XPE2/ XPG2
Edison 3030
Lumileds Luxeon3030
Nichia 757D
Osram Oslon square

LL12ZZ-CRC60145L19



FWHM 60x145°
DxWxH(mm) 50 x 50 x 50
Cree XPE2/ XPG2
Edison 3030
Lumileds Luxeon3030
Nichia 757D
Osram Oslon square

LL12ED-VT85160L02

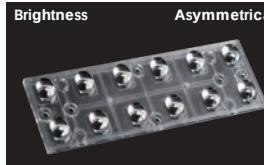


FWHM 85x160°
DxWxH(mm) 158 x 50 x 9.4
Cree MHB
Edison 1LA5

LL16SE-BQL45145L51




FWHM 45x145°
DxWxH(mm) 167.6 x 73.6 x 7.6
Seoul MJT3030/ 4040/ 5050

LL12ZZ-CRC60155L19

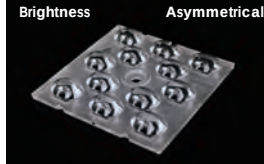

FWHM 60x155°
DxWxH(mm) 50 x 50 x 50
Cree XPE2/ XPG2
Edison 3030
Lumileds Luxeon3030
Nichia 757D
Osram Oslon square

LL14LU-ALY90130L19

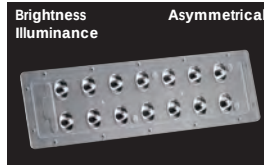


FWHM 90x130°
DxWxH(mm) 250 x 60 x 9.3
Cree XPL-HD
Lumileds Rebel ES/Luxeon T
Nichia NVS19B/757D
Seoul Z5M1/M2/Z8Y15/19

LL18SE-CBZ50150L51




FWHM 50x150°
DxWxH(mm) 198 x 68 x 7.6
Seoul MJT3030/ 4040/ 5050

LL12OS-EL50130L02

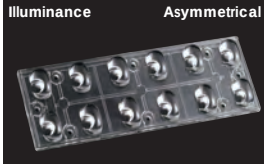


FWHM 50x130°
DxWxH(mm) 158.4 x 50.3 x 9.1
Cree MHB

LL14CR-AOC65150L02

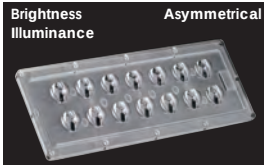


FWHM 65x150°
DxWxH(mm) 260 x 80.2 x 11.7
Cree XT-E/XPL-HD/MHB
Lumileds Luxeon T
Osram Oslon SSL 80/150/Square
Seoul Z5M1/M2

LL20CR-VK60140L02

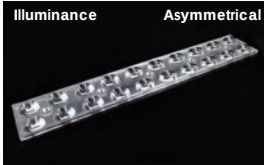

FWHM 60x140°
DxWxH(mm) 319.3x52.3x14.6
Cree XP-E/XP-G
Lumileds Luxeon T
Osram Oslon SSL80/150/Square
Nichia NVS19B
Seoul Z5M1/M2/Z8Y15/19

LL22SE-CBZ50150L51

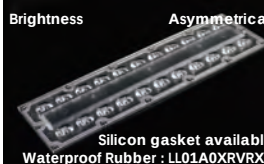


FWHM 50x150°
DxWxH(mm) 238 x 68 x 7.6
Seoul MJT3030/ 4040/ 5050

LL24CR-AU75135L02



FWHM 75x135°
DxWxH(mm) 120 x 100 x 10.2
Cree XP-E(G2)/XPL-HD/XT-E/XBD/XML-2
LGInnotek H35A
Lumileds Rebel(ES)/ Luxeon A(T)
Nichia NVS19B/757D
Osram Oslon SSL80/150/Square
Edison Federal 3045
Seoul Z5M1/M2/Z8Y15/19

LL30CR-PT60140L02

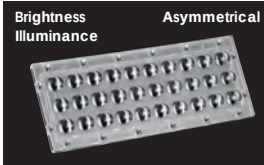

FWHM 60x140°
DxWxH(mm) 235 x 71 x 9.4
Cree XP-E2(G2)/XT-E/MHB
LGInnotek H35A
Lumileds Luxeon T
Nichia NVS19B
Osram Oslon SSL80/150/Square
Seoul Z5M1/M2

LL24LU-JT60120L02



FWHM 60x120°
DxWxH(mm) 126 x 110 x 10.5
Lumileds Rebel (ES)/Luxeon T
Nichia NVS19B
Osram Oslon SSL80/150/Square
Seoul Z5M1/M2

LL28SE-CBZ50150L51



FWHM 50x150°
DxWxH(mm) 158.3x98.03x7.6
Seoul MJT3030/ 4040/ 5050

LL36SE-CBZ50150L51




FWHM 50x150°
DxWxH(mm) 188 x 98 x 7.6
Seoul MJT3030/ 4040/ 5050

LL24OS-JT110150L02



FWHM 110x150°
DxWxH(mm) 126 x 110 x 9
Lumileds Rebel/Rebel ES
Nichia NVS19B
Osram Oslon SSL 80/150/Square
Seoul Z5M1/M2

LL28CR-UI65140L14

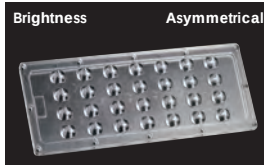

FWHM 65x140°
DxWxH(mm) 259.5x79.7x12.2
Cree XP-E(G2)/XT-E/MHB
XPL-HD/XM-L2
Lumileds Rebel ES/Luxeon T
Nichia NVS19B/757D
Osram Oslon SSL80/150/Square
Seoul Z5M1/M2/Z8Y15/19

LL01CR-BZT80140L83-Mx



FWHM 80x140°
DxWxH(mm) 67 x 35
Cree CXA15xx

★ Cree



★ Nichia



★ Lextar



★ Samsung



★ LGInnotek



★ Osram



★ Edison



★ Seoul



★ Lumileds

