




## Silicone Cover Stranded-Core Wire - 2m 26AWG Gray

PRODUCT ID: 1884

There are multiple versions of this item. Please select one from the options below:

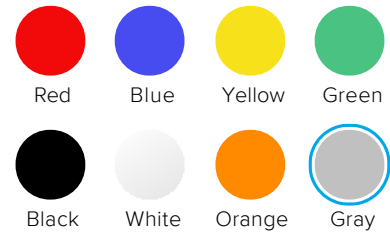

There are multiple versions of this item. Please select one from the options below:

2m

25ft

IN STOCK

1

ADD TO CART

1-9

10-24

25-49

50+

ADD TO WISHLIST

DESCRIPTION

TECHNICAL DETAILS

## DESCRIPTION

Silicone-sheathing wire is super-flexible and soft, and its also strong! Able to handle up to 200°C and up to 600V, it will do when PVC covered wire wimps out. We like this wire for being extremely supple and flexible, so it is great for wearables or projects where the wire-harness has to be able to deal with a lot of bending.

Comes with 2m of **grey** wire. The wire is 26AWG stranded with an outer diameter of 1.5mm.





## TECHNICAL DETAILS

- Length: 2 meters / 78.7"
- Outer Diameter: 1.4mm / 0.06"
- Nominal Voltage: 600V
- Temperature Range: -60°C ~ 200°C
- OD Tolerance: ±0.1mm
- Resistance: 123 Ω/Km
- Current Handling Capability: ~3.5 A (depends on length!)



## LEARN



3D Printed Unicorn Horn  
Glowing majesty two ways

## MAY WE ALSO SUGGEST...



"Wire Wrap" Thin



Silicone Cover Stranded-



Silicone Cover Stranded-



Solid-Core Wire Spool - 25ft



Silicone Cover Stranded-



Silicone Cover Stranded-



Solid-Core Wire Spool - 25ft



Silicone Cover Stranded-



Silicone Cover Stranded-



Solid-Core Wire Spool - 25ft



Silicone Cover Stranded-



Silicone Cover Stranded-

## DISTRIBUTORS [EXPAND TO SEE DISTRIBUTORS](#)

[CONTACT](#)

[SUPPORT](#)

[DISTRIBUTORS](#)

[EDUCATORS](#)

[JOBS](#)

[FAQ](#)

[SHIPPING & RETURNS](#)

[TERMS OF SERVICE](#)

[PRIVACY & LEGAL](#)

[ABOUT US](#)

ENGINEERED IN NYC Adafruit®

*"I don't think there's anything like  
saving someone's life to bring you  
satisfaction and happiness" -*

**Stephanie Kwolek**



4.9 ★★★★★  
Google  
Customer Reviews