




Part Number : [150190297](#)

Product Description : 1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 127.00mm Cable Length, Gold (Au) Plating, 14 Circuits

Series Number : 15019

Status : Active

Product Category : Flat-Flexible Cable (FFC)

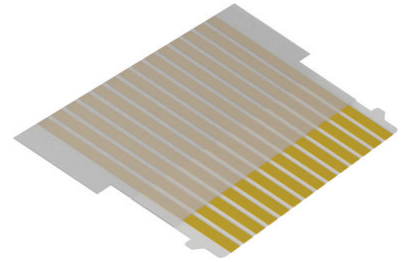

Documents and Resources

Drawings

[150190297_sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[150190001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15019
Description	1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 127.00mm Cable Length, Gold (Au) Plating, 14 Circuits
Product Name	Premo-Flex FFC Jumper
UPC	196823473203

Electrical

Current - Maximum per Contact	1.25A
Voltage - Maximum	60V AC

Physical

Cable Length	127.00mm
Circuits (Loaded)	14
Contact Layout Type	A (same side)
Design Feature	Superior Retention
Material - Outer Jacket	Polyester
Material - Plating Mating	Gold
Net Weight	1.686/g
Packaging Type	Bag
Pitch - Mating Interface	1.00mm

Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flexible Cable (FFC)
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 1.00mm Pitch, FD19 Series, Right- Angle, Bottom Contact, 1.90mm Height, 14 Circuits, Gold over Nickel Plating	<u>2005280140</u>

This document was generated on May 13, 2026