


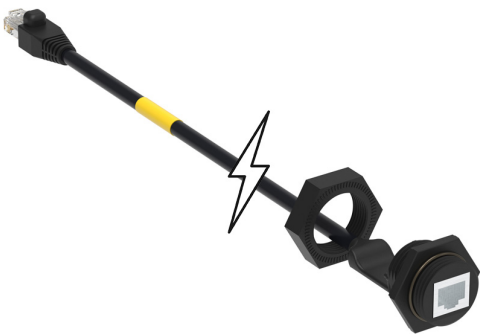

Part Number : [1300550002](#)
Product Description : Brad RJ-Lnxx Industrial Ethernet Receptacle, Female (Straight) to Male (Straight) Front Panel Mount, 10Base T, Solder PCB and Cable Termination, 0.305m (1.0') Length
Series Number : 130055
Status : Active
Product Category : Circular Industrial Connectors
Engineering Number : ENSP1F5C305



Documents & Resources

Drawings
[1300550002_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

Part Details

General

Status	Active
Category	Circular Industrial Connectors
Series	130055
Description	Brad RJ-Lnxx Industrial Ethernet Receptacle, Female (Straight) to Male (Straight) Front Panel Mount, 10Base T, Solder PCB and Cable Termination, 0.305m (1.0') Length
IP Rating	IP67
Product Name	Brad,RJ-Lnxx
Type	Adapter
UPC	78678844697

Electrical

Current - Maximum per Contact	1.5A
Voltage - Maximum	125V DC

Physical

Coupling Type	External Thread
Gender	Male
Keyway	None
Length	0.305m
Material - Component	ABS
Mounting Thread Size	1" - 14 UNC
Net Weight	35.273/g
Orientation	Straight
Panel Mount	Front
Poles	N/A
Temperature Range - Operating	-20° to +80°C
Wire/Cable Type	N/A
Wire Size (AWG)	N/A

This document was generated on Apr 26, 2025