
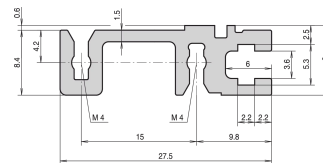


# Horizontal Rail, Rear, Type H-ST, Heavy, Standard, 63 HP

## CATALOG NUMBER

**34560-563**

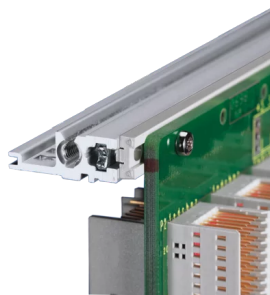

Combinations of horizontal rails and side panels

|                                  | Light rail | Standard rail | Heavy rail | Heavy rail with insulation strip |
|----------------------------------|------------|---------------|------------|----------------------------------|
| Light rail                       | -          | +             | +          | +                                |
| Standard rail                    | +          | +             | +          | +                                |
| Heavy rail                       | +          | +             | +          | +                                |
| Heavy rail with insulation strip | +          | +             | +          | +                                |
| Horizontal rail                  | +          | +             | +          | +                                |
| Side panel                       | Light rail | Standard rail | Heavy rail | Heavy rail with insulation strip |

The horizontal rail, type ST enables the isolated assembly of a backplane. The isolation is done by an insulation strip.

## CERTIFICATIONS



## FEATURES

For indirect backplane mounting with insulation strip

Standard where mechanical demands are high (H-ST)

Mounting top and bottom

< 28 HP not printed

Aluminum extrusion, anodized finish, conductive contact surface, with HP markings

PRODUCT ATTRIBUTES

|                                                                                |
|--------------------------------------------------------------------------------|
| Product Type: Horizontal Rail                                                  |
| Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO |
| Type: Heavy, ST                                                                |
| Rack Width: 63HP                                                               |
| Package Quantity: 1                                                            |
| Finish: Anodized                                                               |
| Material: Aluminum                                                             |

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE