

[Application Tooling](#) > [Applicators](#)

OC-AT-E-FA-080F110OV-040-0927



✓ **ACTIVE**

AMP

TE Part # **2150424-2**

TE Internal #: **2150424-2**

Feed Type : **Pneumatic**

Applicator Style : **OCEAN**

Application Interface : **Male Adapter Post - Atlantic Style**

Service Options : **Capability Study, Crimped Samples, Cross Section - Photograph**

Terminator Type : **30 mm (1.12") Stroke**

Terminator, 40 mm (1.62") Stroke Terminator

 [Add to List](#) ▼

| [Similar Products](#)

Compatible Parts & Tooling

SHOP OUR DISTRIBUTORS

North America ▼

Request pricing, availability and customization options

[CONTACT US](#)



We are here to help!

Get in touch with our product experts.



[CHAT WITH US](#)



[EMAIL US](#)



[CALL US](#)

DOCUMENTS

FEATURES

PRODUCT COMPLIANCE

Product Drawings

Customer Accessible Production Drawing
OC-AT-E-FA-080F110OV-040-0927

 [OC-AT-E-FA-080F110OV-040-0927](#) English

Please review product documents or [contact us](#) for the latest agency approval information.

Other

Feed Type : **Pneumatic**

Applicator Style : **OCEAN**

Application Interface : **Male Adapter Post - Atlantic Style**

Service Options : **Capability Study, Crimped Samples, Cross Section - Photograph**

Terminator Type : **30 mm (1.12") Stroke Terminator, 40 mm (1.62") Stroke Terminator**

Alignment Aids : **Alignment Gauge, Camera**

Compatible Parts



TE Part # 1-1633384-3
**ANVIL,
COMBINATION**

View Product



TE Part # 1633963-1
**CRIMPER,
INSULA... PREMIUM**

View Product



TE Part # 2217206-7
Blade, Slug

View Product




TE Part # 3-456405-7
**CRIMPER, WIRE
.080 "F"**

View Product


Customers Also Bought




TE Part # 7-2151375-7
**OC-055F075F-
CRIMPTOOLINGKIT**

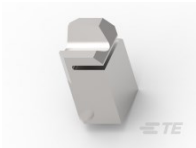

 TE Part # 1803095-1
**FLOATING SHEAR,
FRONT**



 TE Part # 2161500-1
**AMP 5K/40 CE
TERMINATOR**



TE Part # 1725900-3
**AMP-5K/30
TERMINATOR**