


Female headers

BL 5 025 3

Innenfederkontakt Oberfläche: Ni + 0,25µm Au

[add to](#)

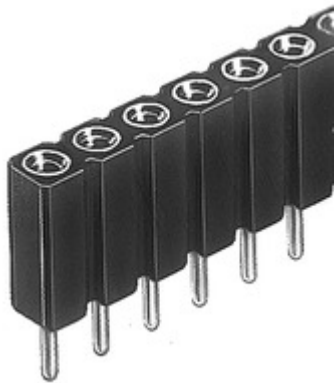

[Features](#) [Technical Drawing](#) [Accessories / related products](#)

no. of contacts

3

contact material	CuZn-Legierung
contact sleeve	tin-plated
surface contact / contact sleeve	Ni+4...6µm Sn
contact spring	gold-plated
inner contact spring material	CuBe-Legierung
inner contact spring surface	Ni + 0,25µm Au
Typ Innenfeder	6-Finger
plugability	□ 0,55 mm bis □ 0,65 mm Ø 0,65...0,85 mm
insertion depth	2,5 ... 6,0 mm
plug-in cross-section	square 0.635 Ø 0.65 to 0.85
insertion / extraction force	1,3 N / 0,3 N
shock resistance	50 g
vibration resistance max.	15 g
volume resistivity	≤10 mΩ
capacity between two adjacent contacts	≤ 0,3 pF
nominal current	3 A
nominal voltage	150 V DC
test voltage	1500 V
material isolation body	PA 4.6, GF
temperature range	-40 °C ... +163 °C (260 °C / 10 s)
class of flammability	UL 94 V-0
insulation resistance	>10 ¹² Ω
version	standard
connection type	soldering
reflow solderable	yes