


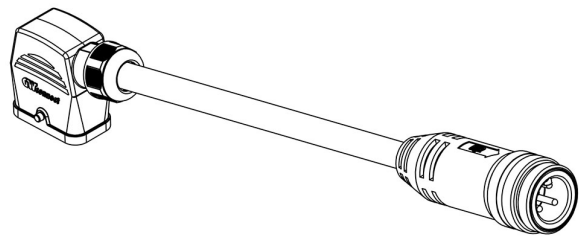

**Part Number :** [1302490122](#)  
**Product Description :** BradPower D-Size (1 3/8"-M35) 4-Pole Straight Male to GWConnect Heavy Duty Connector S-QD 4/2 90° Female, 10 AWG, Black TPE Cable, 5.0m (16.40') Length  
**Series Number :** 130249  
**Status :** Active  
**Product Category :** Circular Industrial Cordsets  
**Engineering Number :** 130249-0113-M050



Documents & Resources

Drawings  
[1302490122\\_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Reviewed per 2000/53/EC
Low-Halogen Status	Not Relevant
REACH SVHC	Not Reviewed per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

## Part Details

### General

Status	Active
Category	Circular Industrial Cordsets
Series	130249
Description	BradPower D-Size (1 3/8"-M35) 4-Pole Straight Male to GWConnect Heavy Duty Connector S-QD 4/2 90° Female, 10 AWG, Black TPE Cable, 5.0m (16.40') Length
IP Rating	IP67
Product Name	BradPower D-Size
Type	Double Ended
UPC	78172556598

### Electrical

Current - Maximum per Contact	32.0A
Voltage - Maximum	600V

### Physical

Cable Diameter	13.46mm (.530")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Black
Connector End A	HDC
Connector End B	BradPower D-Size (1 3/8"-M35)
Coupling Style	Latching, Threaded
Gender	Female-Male
Keyway	Single
LED Indicator	None
Material - Cable Jacket	TPE
Material - Connector Body	Polyamide, TPE
Material - Contact	Copper Alloy
Material - Coupling Nut	Anodized Aluminum

Material - Plating Mating	Gold, Silver
Net Weight	548.000/g
Orientation	90° to Straight
Poles	4
Temperature Range - Operating	-40° to +90°C
Wire/Cable Type	TC-ER
Wire Size (AWG)	10

---

This document was generated on Mar 13, 2025

---