
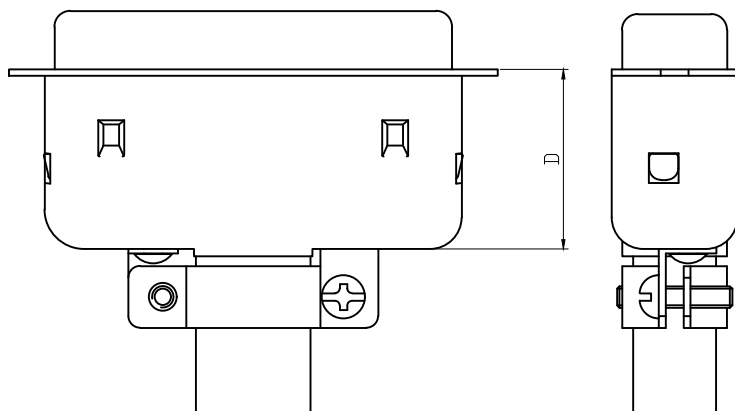


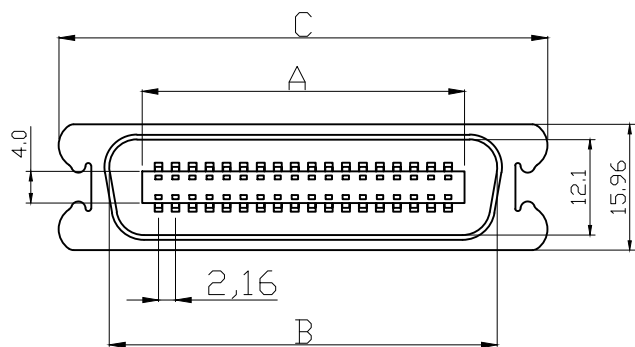

Male (With Metal cover)

Product Specification

Material

Insulator :Glass-Filled Thermoplastic PBT,UL94V-0 rated, Blue
Contact :Brass , Gold flash selective gold
Shell :Steel, 100u" Tin Over 50u" min Nickel.

Electrical

Contact Resistance :20 milliohms Max at 1 AMP DC.
Insulation Resistance :1000 magohms at 500 VDC
Dielectric Withstanding Voltage :1000 VAC/rms 60Hz for 1 minute
Current Rating :5 AMP
Volatge Rating :250 VAC/rms 60Hz

③ Recommended Wire gage : 24AWG~30AWG

Dimensions

Positions	A	B	C	D
14	17.32	25.50	38.08	21.40
24	27.94	36.20	49.28	20.40
50	56.32	64.30	77.00	24.74

RoHS compliant

Scale	1:1					Date	Name	Customer-No.
TOLERANCE					Drawn	30.06.2009	Dean	
X.	±0.38				Approved	11.02.2022	Daniel	ASSMANN WSW-No.
X.X	±0.25							A-57/xx M
X.XX	±0.13	③	Add recommended wire gage	11.02.2022	Daniel			Drawing-No.
X°	±3°	②	Cancel 36 Pin	17.06.2016	Ray			ASS 3547 CO
.X°	±1.0°	①	Drawn	30.06.2009	Dean			rev03
		Id.	Modification	Date	Name			Replace
								Sheet

ASSMANN
WSW components