


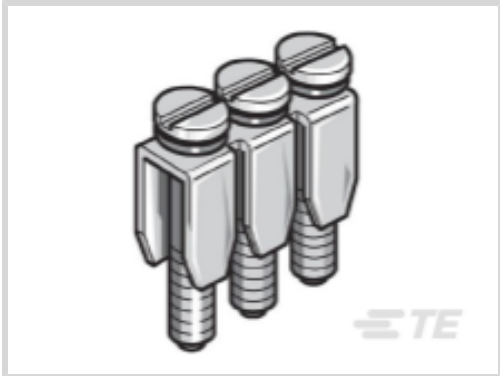

Product Compliance

For compliance documentation, visit the product page on TE.com>


EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought



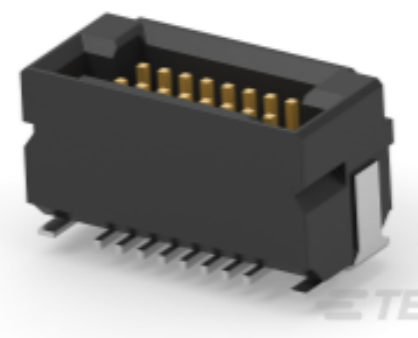

TE Part #454928-E
DRCQ 0,80 16 M 2 SMD M2 137 E009
176 GU-



TE Part #176274-2
AMP UNIVERSAL POWER PLUG 6P



TE Part #3-1571999-6
ADP1004=PIANO DIP SWITCH




TE Part #1734101-6
Champ050 series,60pos,Au over PdNi




TE Part #2149126-3
EMI/Dust Plug




TE Part #2170752-2
CAGE ASSEMBLY, QSFP28 1X1,
GASKET

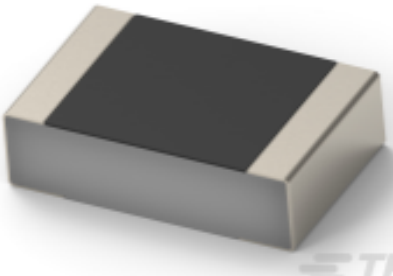

TE Part #9-2176451-2
CPF 0201 442R 0.1% 25ppm 1K RL

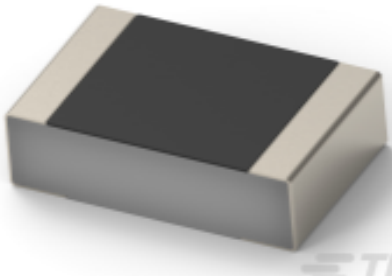

TE Part #6-2176453-6
CPF 0201 27K4 0.1% 25ppm 1K RL

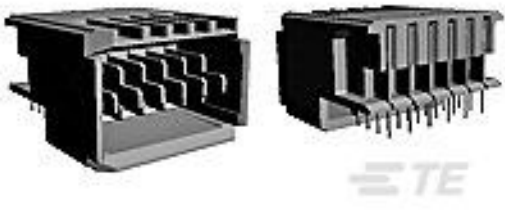

TE Part #5223964-6
UNV,PWR,MDL,HDR,SEQ



TE Part #6450361-1
MBXL R/A RCPT 24S+6P

Documents

Datasheets & Catalog Pages
BJM5-4 POLES

English