


Horizontal Rail, Rear, Center, Type MZ, With Z-Rail, 84 HP

CATALOG NUMBER

34561-284

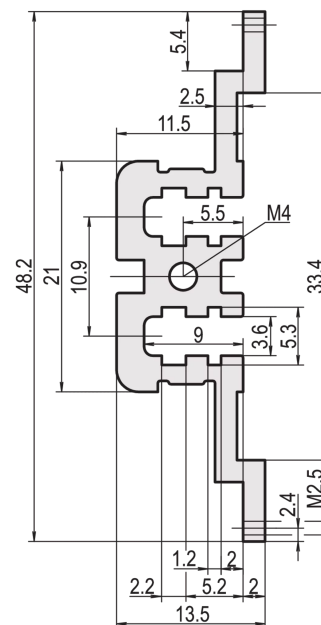

Combinations of horizontal rails and side panels

		"A" = yes, be combined		"X" = combination not recommended	
Horizontal rail	84 HP	-	+	+	+
	84 HP	+	+	+	+
	84 HP	+	+	+	+
Side panel	84 HP	+	+	-	-
	84 HP	+	+	-	-
	84 HP	+	+	-	-
	84 HP	+	+	-	-

The horizontal rail, center, type MZ enables the use of DIN connectors in accordance with EN 60603-2.

CERTIFICATIONS



FEATURES

- For directly mounting connectors complying with EN 60603 (DIN 41612)
- Aluminum extrusion, anodized surface, conductive contact surface, without printed markings

PRODUCT ATTRIBUTES

- Rack Width: 84HP
- Package Quantity: 1
- Finish: Anodized
- Material: Aluminum
- Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
- Product Type: Horizontal Rail
- Type: Type MZ
- Works With: Subracks; Cases

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE