

# C-JCI 1,5 - Connector

3240061

<https://www.phoenixcontact.com/us/products/3240061>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Butt connector, fully isolated, red, 0.5 - 1.5 mm<sup>2</sup>,

## Your advantages

- Electrogalvanized
- Hard-soldered crimping zone for maximum conductor pull-out forces in connection with CRIMPFOX RCI... pliers
- Halogen-free
- Conductor protection against pushing through

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 3240061       |
| Packing unit                         | 50 pc         |
| Minimum order quantity               | 50 pc         |
| Sales key                            | BH34          |
| Product key                          | BH34V1        |
| GTIN                                 | 4046356452793 |
| Weight per piece (including packing) | 1.108 g       |
| Weight per piece (excluding packing) | 1.09 g        |
| Customs tariff number                | 85369010      |
| Country of origin                    | CN            |

# C-JCI 1,5 - Connector

3240061

<https://www.phoenixcontact.com/us/products/3240061>

 


## Technical data

### Product properties

|                  |                                                   |
|------------------|---------------------------------------------------|
| Product type     | Connector                                         |
| Product property | Halogen-free                                      |
|                  | With "Easy Entry" (conical insertion area)        |
|                  | With conductor protection against pushing through |
|                  | PA-insulated                                      |
|                  | Tin-plated                                        |
|                  | Temperature range: -20°C ... +105°C               |
|                  | Flammability rating V2 in accordance with UL 94   |

### Dimensions

|                                           |                                                                                     |
|-------------------------------------------|-------------------------------------------------------------------------------------|
| Dimensional drawing                       |  |
| Sleeve length                             | 25 mm                                                                               |
| Maximum stripping length                  | 7 mm                                                                                |
| Min. material thickness                   | 0.75 mm                                                                             |
| Inner dimensions of the insulating collar | 4 mm                                                                                |

### Material specifications

|                                        |                   |
|----------------------------------------|-------------------|
| Color                                  | red (RAL 3001)    |
| Material                               | Cu                |
| Flammability rating according to UL 94 | V2                |
| Coating                                | electrogalvanized |
| Insulating material                    | PA                |
| Components                             | halogen-free      |

### Mechanical properties

#### Technical data

|               |       |
|---------------|-------|
| Sleeve length | 25 mm |
|---------------|-------|

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -20 °C ... 105 °C |
| Permanent temperature           | 105 °C            |
| Short-term temperature          | 120 °C            |

# C-JCI 1,5 - Connector


3240061

<https://www.phoenixcontact.com/us/products/3240061>



## Drawings

Dimensional drawing

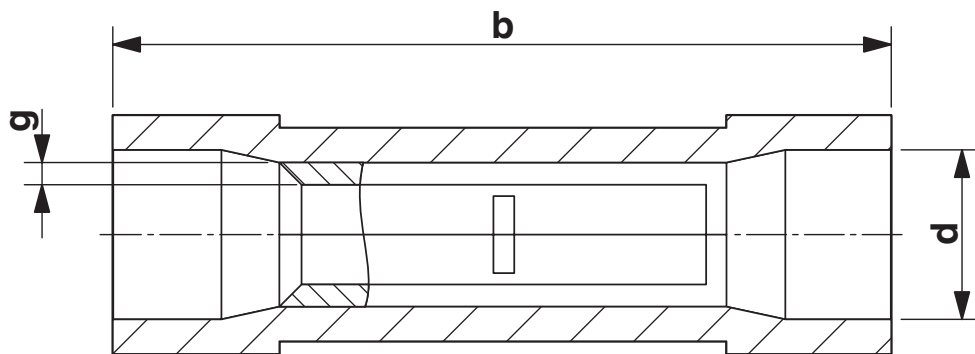

# C-JCI 1,5 - Connector

3240061

<https://www.phoenixcontact.com/us/products/3240061>



## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27400204 |
| ECLASS-15.0 | 27400204 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC001052 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 27121700 |
|-------------|----------|

# C-JCI 1,5 - Connector

3240061

<https://www.phoenixcontact.com/us/products/3240061>



## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)