

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0945069000

Status:

Active

Overview:

Standard Quick-Disconnect Terminals

Description:

Quick Disconnect Safelock Housing, accepts 6.35 x 0.81mm Female Tab Terminal, 14-20 AWG Wire, 1 Circuit

Documents:

3D Model

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

Crimp Housings

Series

94506

Application

Power

Overview

Standard Quick-Disconnect Terminals

Product Name

Quick Disconnect, Safelock

UPC

800754331449

Physical

Breakaway

No

Circuits (maximum)

1

Color - Resin

White

Flammability

94V-2

Gender

Receptacle

Glow-Wire Capable

No

Lock to Mating Part

None

Material - Resin

Nylon

Net Weight

0.572/g

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

N/A

Pitch - Termination Interface

N/A

Polarized to Mating Part

No

Temperature Range - Operating

-40° to +105°C

Solder Process Data

Lead-freeProcess Capability


N/A

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-94506-001

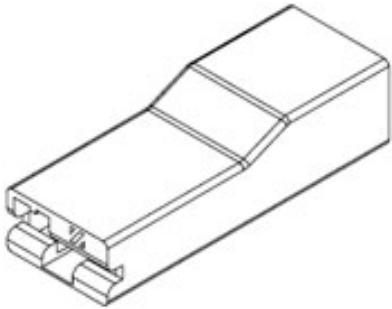

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per

-ED/88/2018 (15

January 2019)

Halogen-Free

Status

Not Relevant

For more information, please visit

Contact US

China ROHS

Not Relevant

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

94506 Series

Use With

945060100

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION