

AWVT00252012R47M00

Search by :

Part Number

Characteristics

Cross reference



MP


Auto

?

Closed Magnetic Circuit Type - Automatic Assembly

- Series Pdf
- RoHSREACHCoC

Product detail		
	L(mm) ±	2.5±0.25
	W(mm) ±	2.0±0.25
	T(mm) ±	1.2±0.05
	Inductance(uH)	0.47
	Tolerance(±%)	20
	Test Frequency	1MHz,200mV
	RDC(ohm)	0.027
	RDC Tolerance(±%)	30
	Isat(A)Typ	3.7
	Isat(A)Max	3.3
	Irms(A)Typ	3.1
	Irms(A)Max	2.7
	Operating Temperature	−40℃~125℃

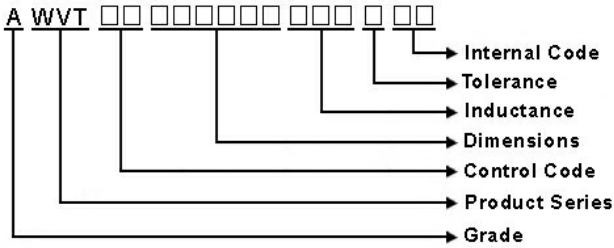

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.