


AUTOMOTIVE SEALS & CAVITY PLUGS

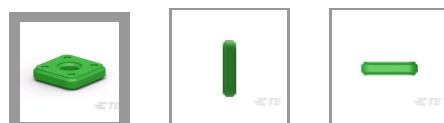

✓ Active

TE CONNECTIVITY (TE)

SINGLE WIRE SEAL,AMP MCP6.3/4.8K

9-2141264-2

TE Internal Number: 9-2141264-2

EU RoHS Compliant

EU ELV Compliant

Seal Type Family Seal

Cable Insulation Diameter 9.3 – 9.9 mm [.366 – .389 in]

Material Other

Operating Temperature Range -40 – 140 °C [-40 – 284 °F]

Color Green

 **PRODUCT DRAWING**
English

 **3D PDF**

DOCUMENTATION

Product Drawings

SINGLE WIRE SEAL,AMP MCP6.3/4.8K Kabeldichtung Einzeln, AMP MCP6.3/4.8K

PDF

English

CAD Files

3D PDF

PDF

3D

Customer View Model

2D_DXF.ZIP

English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Seal Type Family Seal

Body Features

Material Other

Color Green

Dimensions

Cable Insulation Diameter 9.3 – 9.9 mm [.366 – .389 in]

Usage Conditions

Operating Temperature Range -40 – 140 °C [-40 – 284 °F]

Industry Standards

UL Flammability Rating None

Packaging Features

Packaging Method Carton

Packaging Quantity 300

Statement of Compliance

Statement of Compliance

PDF