




Canvas React

Kingston's Canvas React™ microSD card is designed to be as fast as you are, capturing 4K video or taking stunning burst-mode photos when the action doesn't stop. This card is tested to be durable¹, so you can be confident that your memories will be safe when using your DSLR, mirrorless camera or flagship Android™² phone. It's available in multiple capacities up to 512GB³, to provide plenty of space to capture an entire shoot.

-  Ideal for shooting burst-mode photos and 4K video
-  Class 10 UHS-I U3 speeds up to 100MB/s read, 80MB/s write⁴
-  Multiple capacities up to 512GB³

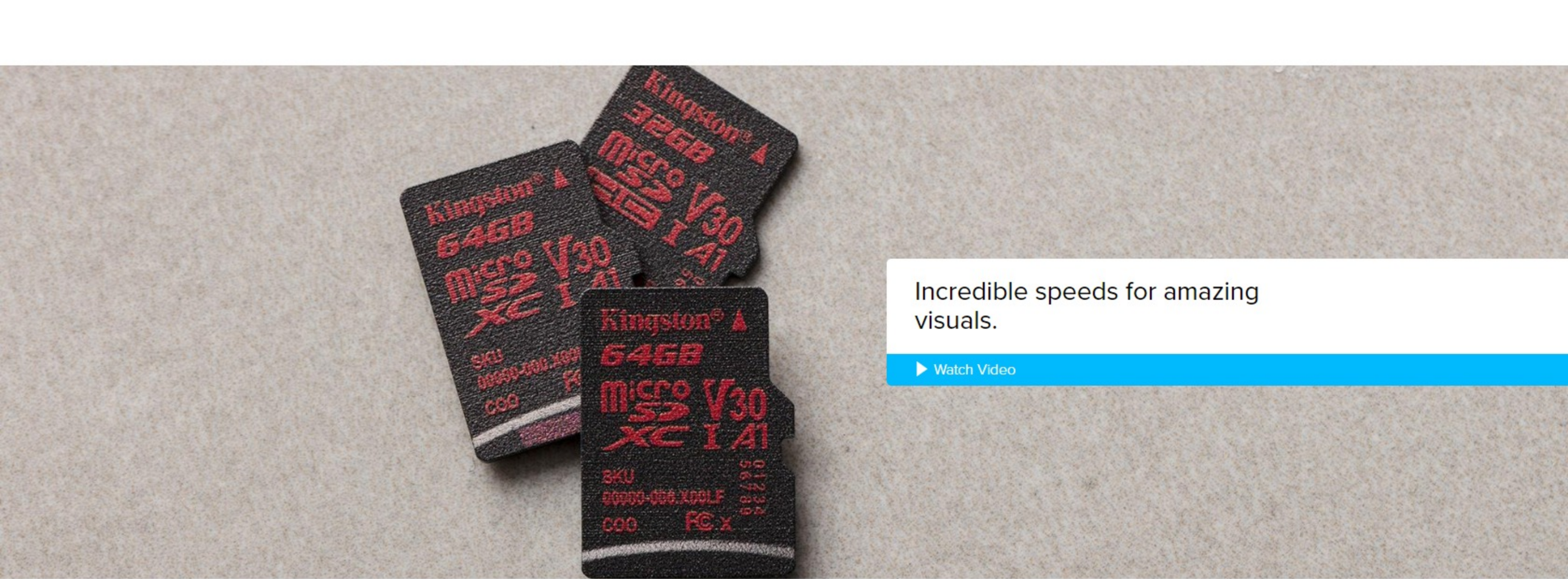

Capacity

- 32GB
- 64GB
- 128GB
- 256GB
- 512GB

Adapter

- SD Adapter
- None

- Part Number: SDCR/256GB

 Where To Buy

Specifications

Capacities ³	32GB, 64GB, 256GB, 512GB
Performance ⁴	32GB – 100MB/s read and 70MB/s write, UHS-I Video Speed Class (V30) 64GB – 512GB – 100MB/s read and 80MB/s write, UHS-I Video Speed Class (V30)
Dimensions (microSD)	11mm x 15mm x 1mm
Dimensions (with SD adapter)	24mm x 32mm x 2.1mm
Format	FAT32 (SDHC 32GB), exFAT (SDXC 64GB-512GB)
Operating Temperatures	-25°C to 85°C
Storage Temperatures	-40°C to 85°C
Voltage	3.3V
Warranty	Lifetime

Resources

[Storage Chart](#)
[Compare microSD Cards](#)

[Caring for your Flash Memory](#)
[Warranty](#)

- IEC/EN 60529 IPX7 certified for protection against continual water submersion up to 30 minutes and depth up to 1m. Withstands temperature range from -25 °C to 85 °C. Based on MIL-STD-883H, METHOD 2002.5 military standard test method. Protected against X-ray exposure based on ISO7816-1 guidelines.
- Android is a trademark of Google LLC.
- Some of the listed capacity on a Flash storage device is used for formatting and other functions and thus is not available for data storage. As such, the actual available capacity for data storage is less than what is listed on the product. For more information go to Kingston's [Flash Memory Guide](#).
- Speed may vary due to host and device configuration.

Company

About
Contact
Press

Compliance

Social/Environmental
Supply Chain Management

Legal

Terms of Use
Privacy Statement
Cookie Policy
EU-US Privacy Shield
Warranty

Website

Feedback