


Thermofit<sup>®</sup> Molded Parts  
Specification Control Drawing  
Limited Distribution

Part Number : 462A42X-X-01  
Description : Slimline Transition, 4 Entry

NOTES

- 1. All dimensions are in inches  
[millimeters]
- 2. Dimensions appearing in table are as follows:  
a - As Supplied  
b - After Unrestricted Recovery
- 3. Coating is optional. As supplied dimensions appearing in table are for uncoated parts. When coating is added, entry diameters will be reduced by .06 max.

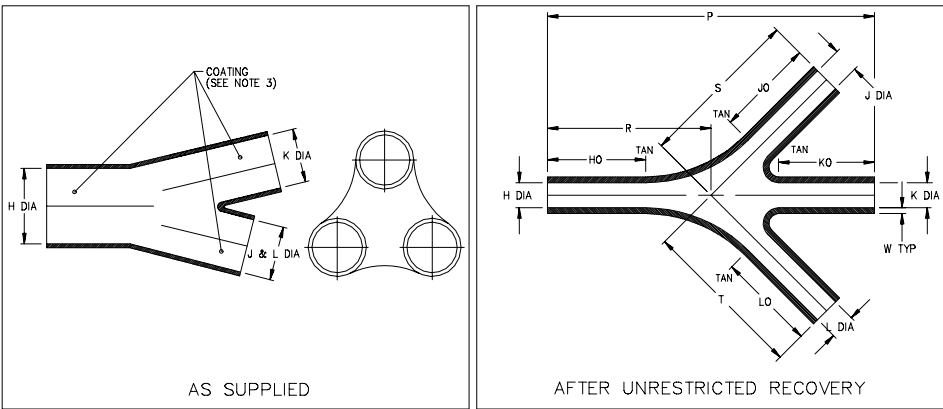

| TABLE OF DIMENSIONS |                       |                       |                       |                       |                            |                     |                        |                        |
|---------------------|-----------------------|-----------------------|-----------------------|-----------------------|----------------------------|---------------------|------------------------|------------------------|
| PART NUMBER         | H                     |                       | J,K & L               |                       | HO,JO,KO & LO<br>±15%<br>b | W<br>Nom<br>b       | P<br>Nom<br>b          | R,S & T<br>Nom<br>b    |
|                     | Min<br>a              | Max<br>b              | Min<br>a              | Max<br>b              |                            |                     |                        |                        |
|                     |                       |                       |                       |                       |                            |                     |                        |                        |
| 462A423-X-01        | <u>2.37</u><br>[60,2] | <u>.79</u><br>[20,1]  | <u>1.42</u><br>[36,1] | <u>.79</u><br>[20,1]  | <u>1.09</u><br>[27,6]      | <u>.06</u><br>[1,5] | <u>5.34</u><br>[135,6] | <u>2.67</u><br>[67,8]  |
| 462A424-X-01        | <u>3.93</u><br>[99,8] | <u>1.31</u><br>[33,3] | <u>2.16</u><br>[54,9] | <u>1.31</u><br>[33,3] | <u>1.78</u><br>[45,2]      | <u>.07</u><br>[1,8] | <u>8.16</u><br>[207,2] | <u>4.08</u><br>[103,6] |

If this document is printed it becomes uncontrolled.  
Check for the latest revision.

**Raychem**  
RAYCHEM CORPORATION  
300 CONSTITUTION DRIVE  
MENLO PARK, CALIFORNIA 94025

Revision : K  
Date : 6/9/99

Part Number : 462A42X-X-01  
Description : Slimline Transition, 4 Entry

Thermofit<sup>®</sup> Molded Parts  
Specification Control Drawing  
Limited Distribution

Part Number : 462A42X-X-01  
Description : Slimline Transition, 4 Entry

| COMPATABILITY CHART |                      |         |                   |                |                     |
|---------------------|----------------------|---------|-------------------|----------------|---------------------|
| MATERIAL DASH NO.   | MATERIAL DESCRIPTION | RT SPEC | COATING SLASH NO. | COATING S NO.  | COATING DESCRIPTION |
| -50                 | Flexible, VPB        | RT-1313 |                   |                |                     |
| -51                 | Flexible, EPB        | RT-1321 | /86,/164          | S-1048, S-1124 | Adhesive            |
| -71                 | Flexible, Polyolefin | RT-1316 | /42               | S-1017         | Adhesive            |
|                     |                      |         |                   |                |                     |
|                     |                      |         |                   |                |                     |
|                     |                      |         |                   |                |                     |

ORDERING INFORMATION

462A42X-X-01/XX

Base part number

Material dash number  
(See Compatability Chart)

Modification number  
(If necessary, see front of scd binder  
for a complete list)

Adhesive slash number  
(If necessary, see Compatability Chart)

THIS DRAWING IS SUBJECT TO CHANGE WITHOUT NOTICE; CONSULT YOUR  
NEAREST FIELD REPRESENTATIVE FOR CURRENT REVISION

**Raychem**  
RAYCHEM CORPORATION  
300 CONSTITUTION DRIVE  
MENLO PARK, CALIFORNIA 94025

Revision : K  
Date : 6/9/99

Part Number : 462A42X-X-01  
Description : Slimline Transition, 4 Entry