




- Home
- Products
- Online Catalog
- Request Quote
- Order Online
- Check Stock
- Request Print Catalog
- Request Samples
- Engineering Data
- Distributors
- Capabilities Brochure

CALL NOW:
203 888-2133



Home > 3/16 Round Female Standoffs

3/16 ROUND FEMALE STANDOFFS

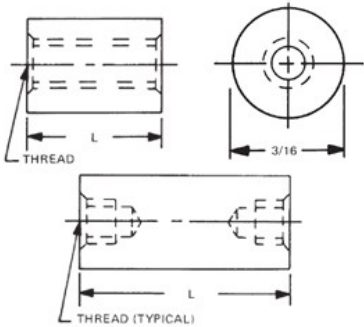

[Home](#) [Previous](#) [Next](#)
[Related Metric](#)

Ordering Code			
xxxxx	xxx	xx	x
Length	Thread	Material	Finish

PART: 1633 256 SS

Red ?'s show missing selections. [Help](#)

- [Thread depth information](#)
- [Material Specifications](#)
- [Ordering non-standard items](#)
- [Download a Drawing](#)

Add to Cart

Qty1 *

Qty2

Qty3

Length *		
Select	Part No.	Length
☐	1631A	3/32
☐	1631	1/8
☐	1631T	5/32
☐	1632	3/16
☐	1632T	7/32
☒	1633	1/4
☐	1633T	9/32
☐	1634	5/16
☐	1634T	11/32
☐	1635	3/8
☐	1635T	13/32

Thread *		
Select	Code	Length
☒	256	2-56
☐	440	4-40

Material *			
Select	Code	Material	RoHS
☐	AL	Aluminum	YES
☐	B	Brass	YES
☒	SS	Stainless Steel	YES
☐	S	Steel	YES
☐	N	Nylon	YES
☐	PH	Phenolic	YES

Finish *	
☒	Plain Finish
☐	1-Cad clear chromate/commercial*
☐	2-Cad clear chromate*
☐	3-Cad yellow chromate*
☐	4-Chrome over nickel
☐	5-Nickel
☐	6-Gold iridite*
☐	7-Clear iridite
☐	9-Alodine 1200*
☐	10-Bright chrome

☐	11-Satin chrome	
-----------------------	-----------------	--