
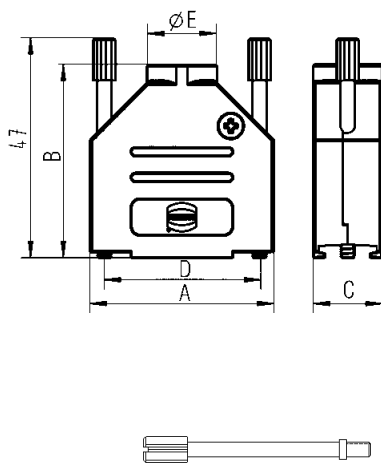
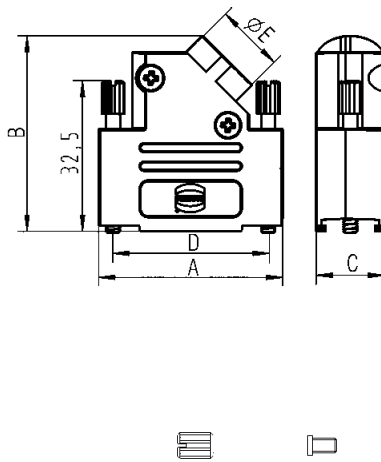


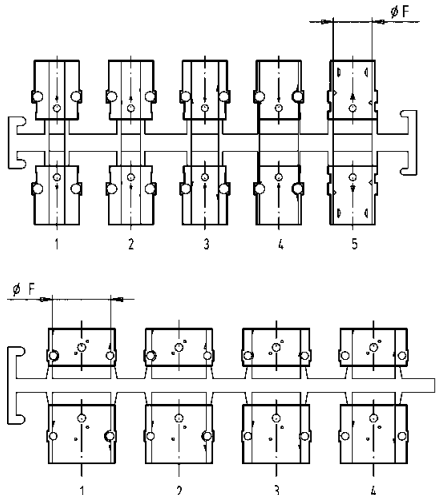

Full metal top and side entry hoods with knurled screws

Identification	No. of contacts	Part number	Drawing	Dimensions in mm																																				
Top entry hood incl. grommet set halves Please insert digit for screw option Knurled screw, thread 4-40 UNC ▶ 3 Knurled screw, thread M3 ▶ 8 Spare knurled screw thread 4-40 UNC thread M3	9 15 25 37 50	09 67 009 034 . 09 67 015 034 . 09 67 025 034 . 09 67 037 034 . 09 67 050 034 . 09 67 002 9029 09 67 002 9101		<table><tr><th>Poles</th><th>A</th><th>B</th><th>C</th><th>D</th><th>E</th></tr><tr><td>9</td><td>31.0</td><td>39.5</td><td>14.8</td><td>25.0</td><td>11.7</td></tr><tr><td>15</td><td>39.5</td><td>41.5</td><td>14.8</td><td>33.3</td><td>11.7</td></tr><tr><td>25</td><td>53.5</td><td>48.5</td><td>14.8</td><td>47.0</td><td>11.7</td></tr><tr><td>37</td><td>71.0</td><td>53.0</td><td>14.8</td><td>63.5</td><td>11.7</td></tr><tr><td>50</td><td>67.5</td><td>54.0</td><td>18.7</td><td>61.1</td><td>17.0</td></tr></table>	Poles	A	B	C	D	E	9	31.0	39.5	14.8	25.0	11.7	15	39.5	41.5	14.8	33.3	11.7	25	53.5	48.5	14.8	47.0	11.7	37	71.0	53.0	14.8	63.5	11.7	50	67.5	54.0	18.7	61.1	17.0
Poles	A	B	C	D	E																																			
9	31.0	39.5	14.8	25.0	11.7																																			
15	39.5	41.5	14.8	33.3	11.7																																			
25	53.5	48.5	14.8	47.0	11.7																																			
37	71.0	53.0	14.8	63.5	11.7																																			
50	67.5	54.0	18.7	61.1	17.0																																			
Side entry hood incl. grommet set halves Please insert digit for screw option Knurled screw, thread 4-40 UNC ▶ 3 Knurled screw, thread M3 ▶ 6 Spare knurled screw thread 4-40 UNC thread M3	9¹⁾ 15 25 37 50	09 67 009 033 . 09 67 015 033 . 09 67 025 033 . 09 67 037 033 . 09 67 050 033 . 09 67 002 9028 09 67 001 9997		<table><tr><th>Poles</th><th>A</th><th>B</th><th>C</th><th>D</th><th>E</th></tr><tr><td>9</td><td>31.0</td><td>37.7</td><td>14.7</td><td>—</td><td>11.7</td></tr><tr><td>15</td><td>39.5</td><td>42.0</td><td>14.7</td><td>33.3</td><td>11.7</td></tr><tr><td>25</td><td>53.2</td><td>41.3</td><td>14.7</td><td>47.0</td><td>11.7</td></tr><tr><td>37</td><td>69.7</td><td>41.8</td><td>14.7</td><td>63.7</td><td>11.7</td></tr><tr><td>50</td><td>67.4</td><td>44.9</td><td>17.4</td><td>61.1</td><td>17.0</td></tr></table>	Poles	A	B	C	D	E	9	31.0	37.7	14.7	—	11.7	15	39.5	42.0	14.7	33.3	11.7	25	53.2	41.3	14.7	47.0	11.7	37	69.7	41.8	14.7	63.7	11.7	50	67.4	44.9	17.4	61.1	17.0
Poles	A	B	C	D	E																																			
9	31.0	37.7	14.7	—	11.7																																			
15	39.5	42.0	14.7	33.3	11.7																																			
25	53.2	41.3	14.7	47.0	11.7																																			
37	69.7	41.8	14.7	63.7	11.7																																			
50	67.4	44.9	17.4	61.1	17.0																																			
Spare grommet set halves 9-37 poles 50 poles		09 67 002 9092 09 67 002 9094		<table><tr><th colspan="3">Grommet dimensions</th></tr><tr><th rowspan="2">Number</th><th colspan="2">Diameter F</th></tr><tr><th>9-37 poles</th><th>50 poles</th></tr><tr><td>1</td><td>4.0</td><td>15.0</td></tr><tr><td>2</td><td>5.0</td><td>14.0</td></tr><tr><td>3</td><td>7.0</td><td>12.5</td></tr><tr><td>4</td><td>9.0</td><td>11.0</td></tr><tr><td>5</td><td>10.2</td><td>—</td></tr></table>	Grommet dimensions			Number	Diameter F		9-37 poles	50 poles	1	4.0	15.0	2	5.0	14.0	3	7.0	12.5	4	9.0	11.0	5	10.2	—													
Grommet dimensions																																								
Number	Diameter F																																							
	9-37 poles	50 poles																																						
1	4.0	15.0																																						
2	5.0	14.0																																						
3	7.0	12.5																																						
4	9.0	11.0																																						
5	10.2	—																																						

¹⁾ 9-pole hood provided with only one screw on the opposite side of the cable entry.
 Operating temperature for all hoods on this page: -40 °C ... +120 °C