




+ FIBER OPTICS

FIBER OPTIC PATCH CABLE ASSEMBLIES

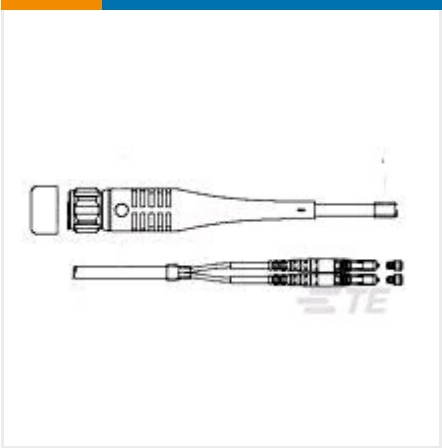

✓ Active

TE CONNECTIVITY (TE)  
FOSM ODC LEAD 5.5 2PLUG - LC/DPX 150M

FullAXS | Fiber Optic , ODC

1-1985844-5  
TE Internal Number: 1-1985844-5

- EU RoHS Compliant with Exemptions
- EU ELV Compliant with Exemptions
- Cable Type Fiber Optic Cable (FOCAB) ODC
- Fiber Diameter (µm) 9/125
- Outside Cable Diameter 5.5 mm [.216 in]
- Number of Fibers 2
- Connector Color (End B) Blue

↓ PRODUCT DRAWING  
English

DOCUMENTATION

Product Drawings

FIBER OPTIC ODC LEAD 2 FOLD PLUG - LC DUPLEX SINGLE MODE 9/125, LONG  
PDF  
English

FEATURES

Please review product documents or [contact us](#) for the latest agency approval information.  
Please Note: Use the Product Drawing for all design activity.

Product Type Features

**Cable Type** Fiber Optic Cable (FOCAB) ODC  
**Mode** Singlemode  
**Connector Type (End A)** Fiber Optic Kit (FOKIT) ODC  
**Connector Type (End B)** LC  
**Connector Style (End A)** Plug  
**Connector Style (End B)** Duplex  
**Fiber Channel** No  
**Product Type** Cable Assembly  
**Cable Assembly Type** Fiber Optic Kit (FOKIT) ODC to LC Duplex

Configuration Features

**Number of Fibers** 2  
**Cable Buffering** Tight Buffer  
**Number of Connectors (End B)** 2

Signal Characteristics

**Return Loss (dB)** 45

Body Features

**Connector Color (End B)** Blue  
**Cable Color** Black  
**Boot Type (Left)** ODC  
**Boot Type (Right)** Bend Limiting  
**Boot Color (Left)** Black  
**Boot Color (Right)** Blue

Dimensions

**Fiber Diameter (μm)** 9/125  
**Outside Cable Diameter** 5.5 mm [ .216 in ]

PRODUCT COMPLIANCE

+

Statement of Compliance

**Statement of Compliance**  
PDF