

Products

Magnetic Buzzer

Magnetic Transducer(External Circuitry Type)

SMD Type

KTG1205

PRINT

Shape

KTG1205



Material	PPS
Rated Voltage (VDC)	5.0
Operating Voltage Range (VDC)	3.0~8.0
Current Consumption (mA)	Max.40
Coil Resistance (Ω)	45.0±6.7
Sound Pressure Level (dBA)	Min.87dBA(Typical 92)@10cm
Rated Frequency (Hz)	2400
Operating Temperature ()	-30~+85
Storage Temperature ()	-40~+85
Weight (Gram)	2.0

Dimension

Part Number Search

Hot Product



Piezo Audio
Transducer(External
Circuitry Type)-SMD
Type

Φ10 x H3.1mm

[More info](#)



Piezo Indicator(Internal
Circuitry Type)-Panel
Mounting Type

Φ40.0xH28.5mm

[More info](#)


NEWS

【electronica
2010】 Hall B6, Booth
No.118 **NEW** [..More
info](#)

【TAITRONICS
2010】 Taipei World
Trade Center
Nangang Exhibition
Hall, Booth
No.L1019/1021 **NEW**
[..More info](#)


KINGSTATE
announces the
partnership with
Denmark-based
company- AM3D **NEW**

[..More info](#)

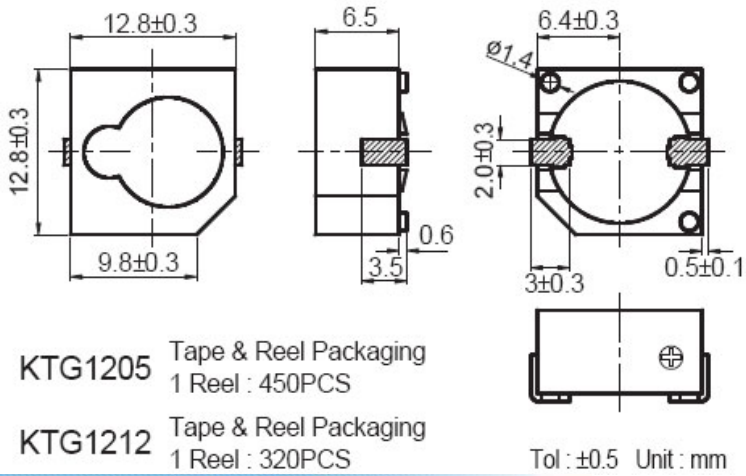

Characteristic / Schematic Diagram

KTG1205

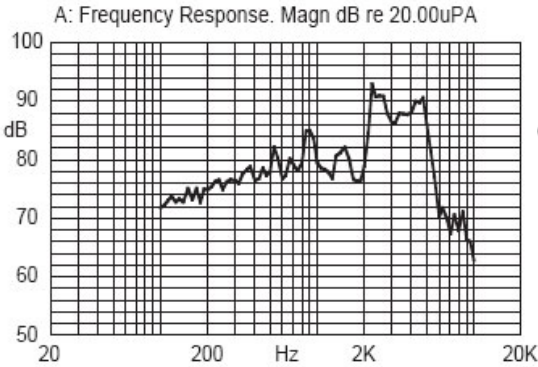

[Back](#)

[TOP](#)

[About Kingstate](#) | [Products](#) | [News](#) | [Investor Relations](#) | [Agent Only](#) | [Career](#) | [Contact Us](#) | [Site Map](#) | [KingState JPN](#)

Copyright 2007. Kingstate Electronics Corp. All Rights Reserved
10F, No. 69-11, Sec. 2, Chung Cheng E. Rd., Tamshui, Taipei County, Taiwan, R.O.C.
TEL: +886-2-2809-5651 FAX: +886-2-2809-7151