


- Quick Links
- Cross reference
- RoHS/LF P/N Search
- Industry Standards
- Alphabetical List
- Documentation
- 3D model search
- Customer drawing search
- Multi Selection Search
- Search by category

Start > Search=10123536-101LF* > 10123536-101LF

10123536-101LF
10123536-101LF - AIRMAX VS2®: 4-Pair, 120 -position, 2 mm pitch, 10 column, 4 Walls, Right Angle Header,standard press-fit, 1 side plating

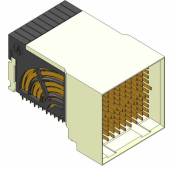

- Customer drawing
- Product Environmental Compliance Report

ACTIVE

RoHS Compliant

Distributor Stock

Print Datasheet

FCI Brings You More

- Contact our sales/technical support
- Sample request

- Specifications
- Download document

Dimensional General Physical	
Dimensional	
Pitch (Slot - min)	20 mm
Spacing (Column)	2 mm
General	
Number of contacts	120
Orientation	Right Angle
Product Series	AirMax VS2
Style	4 Wall Signal Header 2 mm
Termination Style	Standard Press-Fit
Number of columns	10
Number of differential pairs (per column)	4
Physical	
Material (Contact)	Copper Alloy
Material (Housing)	Hi-Temp Thermo Plastic
Plating (Contact)	Au over Ni

Disclaimer : The information above is for reference only. For more technical details, refer to product specification and application specification.