


1981065-1 Product Details

 Share  Print  Email

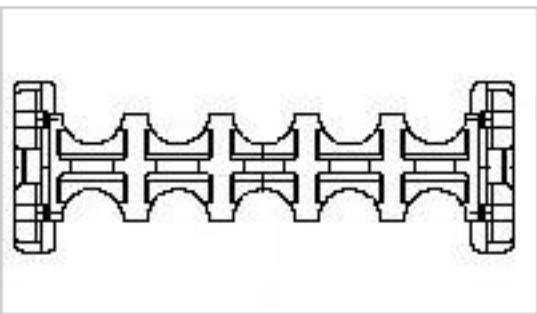

 Active

 View 3D PDF

2, 2.5, 3.3, 3.5, 3.96 & 6.2 Centerline 600 V, 12 A max.

GIC 3.3 10P DBL LOCK PLATE (2ROW,M TYPE)

1981065-1 

TE Internal Number: 1981065-1

Product Highlights [View All](#)

- Grace Inertia Connector Product Line
- Glow Wire Rating = Standard Part - Not Glow Wire
- Accessory
- Accessory Type = Double Lock Plate
- 10 Positions

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

- Documents
- Features**
- Compliance

Please Note:
Use the Product Drawing for all design activity

Product Type Features	
Product Line	Grace Inertia Connector
Product Type	Accessory
Accessory Type 	Double Lock Plate
Accessory Color	Black

Body Features	
Row-to-Row Spacing (mm [in])	4.12 [0.162]

Housing Features	
Centerline (mm [in])	3.30 [0.129]
Housing Material	Nylon 6/6  GF20

Configuration Features	
Number of Positions	10

Industry Standards	
RoHS/ELV Compliance 	RoHS compliant, ELV compliant
Lead Free Solder Processes 	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant

Environmental	
Operating Temperature (°C [°F])	-30 – +105 [-22 – +221]

Conditions for Usage	
Glow Wire Rating	Standard Part - Not Glow Wire
For Use With	Plug Housing

Packaging Features	
Packaging Method	Bag/Box
Packaging Quantity	500

Other	
Brand	TE Connectivity
Comment	Use with Grace Inertia Connector 3.3

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Feedback

Corporate Information

- About TETe InvestorsNews RoomSupplier PortalCareersTerms & ConditionsPrivacy PolicyGlobal Accessibility Statement

Quick Links

- Distributor InventoryProduct Cross ReferenceDocuments & DrawingsProduct Compliance Support CenterSite Map

Customer Support

- Email or Chat With UsFind a Phone NumberKnowledge BaseManage Your Account

Keep Me Informed

