



0.250" (6.35mm) Quick Disconnect Terminals

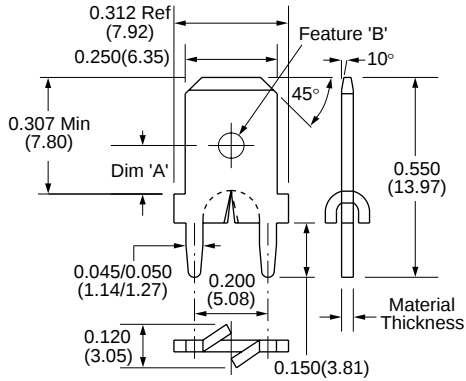

U.S. Patent No. 4,688,866

For exact finish specifications and available special finishes, see Finish Table (page 91).


Loose Part No.	1021	1198
Reeled Part No.	6021-6	6198-6
Feature 'B'	0.070" (1.78mm) Hole	0.070" (1.78mm) Dimple
Dim 'A'	0.134" (3.40mm)	0.160" (4.06mm)
Mounting Type	Stable-Lok™ Splay Outward or Inward	
Material Thickness/ Type	0.032" (0.81mm) Brass	
Standard Finish	Loose: 100% Matt Tin over Copper Reeled: 95/5 Matt Tin/Lead over Copper	
Mounting Hole Diameter	0.058" ±0.003" (1.47mm ±0.076mm)	
Applicator System	Loose: ZPT81-A Reeled: Model 7000, 9700, 9718	

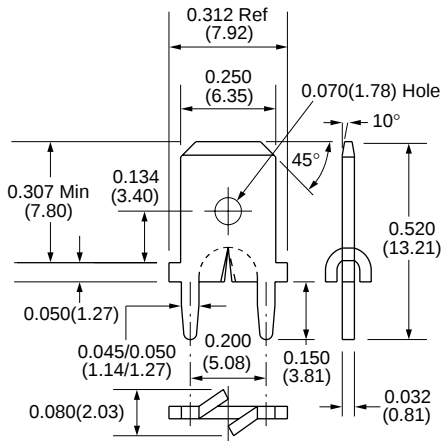

Loose Part No.	1061
Reeled Part No.	6061-6
Mounting Type	Stable-Lok™ Splay Outward or Inward
Material Thickness/ Type	0.032" (0.81mm) Brass
Standard Finish	Loose: 100% Matt Tin over Copper Reeled: 95/5 Matt Tin/Lead over Copper
Mounting Hole Diameter	0.058" ±0.003" (1.47mm ±0.076mm)
Applicator System	Loose: ZPT81-A Reeled: Model 7000, 9700, 9718

U.S. Patent No. 4,688,866

For exact finish specifications and available special finishes, see Finish Table (page 91).

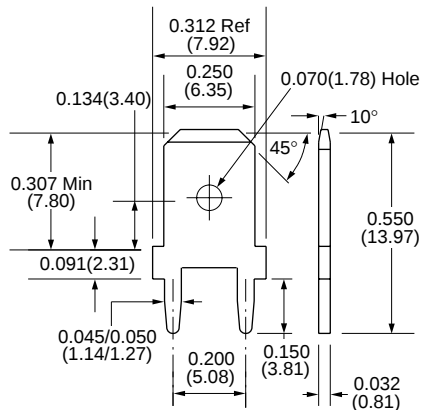

Loose Part No.	836/836-Tape
Reeled Part No.	6836-6
Mounting Type	Outward or Inward Splay
Material Thickness/ Type	0.032" (0.81mm) Brass
Standard Finish	Loose: 100% Matt Tin over Copper Reeled: 95/5 Matt Tin/Lead over Copper
Mounting Hole Diameter	0.058" ±0.003" (1.47mm ±0.076mm)
Applicator System	Loose: ZPT81-A, Model 8000 Reeled: Model 7000, 9700, 9718

For exact finish specifications and available special finishes, see Finish Table (page 91).