




- Home
- Products
- Online Catalog
- Request Quote
- Order Online
- Check Stock
- Request Print Catalog
- Request Samples
- Engineering Data
- Distributors
- Capabilities Brochure

CALL NOW:
203 888-2133



Home > 1/4 Hex Female Standoffs

1/4 HEX FEMALE STANDOFFS

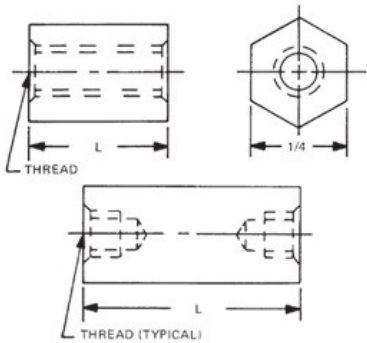

[Home](#) [Previous](#) [Next](#)
[Related Metric](#)

Ordering Code			
xxxxx	xxx	xx	x
Length	Thread	Material	Finish

PART: 2124 832 AL

Red ?'s show missing selections. [Help](#)

- [Thread depth information](#)
- [Material Specifications](#)
- [Ordering non-standard items](#)
- [Request a Drawing](#)

Add to Cart

Qty1 *

Qty2

Qty3

☐	2121	1-9/16
☐	2122	1-5/8
☐	2123	1-11/16
☒	2124	1-3/4
☐	2125	1-13/16
☐	2126	1-7/8
☐	2127	1-15/16
☐	2128	2
☐	2129	2-1/8
☐	2130	2-1/4
☐	2131	2-3/8
☐	2132	2-1/2
☐	2133	2-5/8

Thread *		
Select	Code	Thread
☐	440	4-40
☐	632	6-32
☒	832	8-32
☐	1032	10-32

Material *			
Select	Code	Material	RoHS
☒	AL	Aluminum	YES
☐	B	Brass	YES
☐	SS	Stainless Steel	YES
☐	S	Steel	YES
☐	N	Nylon	YES

Finish *

☒	Plain Finish
☐	1-Cad clear chromate/commercial*
☐	2-Cad clear chromate*
☐	3-Cad yellow chromate*
☐	4-Chrome over nickel
☐	5-Nickel
☐	6-Gold iridite
☐	7-Clear iridite
☐	9-Alodine 1200*
☐	10-Bright chrome
☐	11-Satin chrome
☐	12-Zinc