

Housing - HC-STA-D07-HHFS-1TTM25-EL-AL - 1419231


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sleeve housing D7, for single locking latch, Material: Die-cast aluminum, salt water resistant, Cable outlets: 1, straight, Height: 60.5 mm, Cable gland: none, Gland: Yes, 1x M25, Standard

RoHS

Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 159669
GTIN	4055626159669
Weight per Piece (excluding packing)	40.000 g
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	60.5 mm
Width	34.2 mm
Length	26.9 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
	IP67
Degree of protection of housing (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

Housing - HC-STA-D07-HHFS-1TTM25-EL-AL - 1419231


Technical data

General

Note	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
Size	D7
Housing type	Sleeve housing
Locking type	for single locking latch
No. of cable outlets	1
Cable exit	straight
Screw connection	none
Type of the screw connection	1x M25
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	Uncoated

Drawings

Dimensional drawing

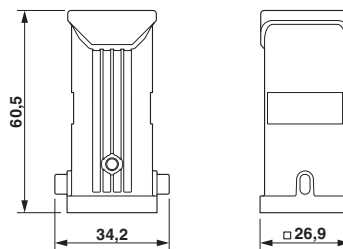

Classifications

eCl@ss

eCl@ss 5.1	27260701
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 5.0	EC000437
ETIM 6.0	EC000437

UNSPSC

UNSPSC 13.2	31261501
-------------	----------

Approvals

Approvals

Housing - HC-STA-D07-HHFS-1TTM25-EL-AL - 1419231


Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		EAC-Zulassung
-----	---	---------------

Accessories

Accessories

Full screw connection

Cable gland - G-INS-M25-M68N-NNES-S - 1411165



Cable gland, Cable gland material: Nickel-plated brass, External cable diameter 11 mm ... 17 mm, Shielding: No, Connecting thread: M25, Color: silver

Cable gland - G-INSEC-M25-S68N-NCRS-S - 1411190



Cable gland, Cable gland material: Nickel-plated brass, External cable diameter 11 mm ... 16 mm, Shielding: yes, Connecting thread: M25, Color: silver

Cable gland - G-INS-M25-M68N-PNES-GY - 1411126



Cable gland, Cable gland material: PA, External cable diameter 11 mm ... 17 mm, Shielding: No, Connecting thread: M25, Color: silver-gray RAL 7001

Housing - HC-STA-D07-HHFS-1TTM25-EL-AL - 1419231

Accessories

Cable gland - G-INS-M25-M68N-PNES-BK - 1411134



Cable gland, Cable gland material: PA, External cable diameter 11 mm ... 17 mm, Shielding: No, Connecting thread: M25, Color: jet black RAL 9005

Labeled device marker

Plastic label - US-EMLP (20X9) CUS - 0830085



Plastic label, can be ordered: By card, white, labeled according to customer specifications, Mounting type: Adhesive, Lettering field: 20 x 9 mm

Phoenix Contact 2017 © - all rights reserved
<http://www.phoenixcontact.com>