

Shape


KMIG1240



Model Number	KMIG1240
Rated Frequency (Hz)	4,000 ± 500
Operating Voltage Range (VDC)	3 ~ 20
Current Consumption (mA)	Max. 8 @12 VDC
Sound Pressure Level (dB)	Min. 83dB@10 cm / 12 VDC
Tone	Continuous
Operating Temperature (°C)	-30 ~ +70
Storage Temperature (°C)	-40 ~ +80
Weight (Gram)	2.6
Material	PPS UL-94 V-0 (Black)

Dimension

Suggested Pad PCB-Layout

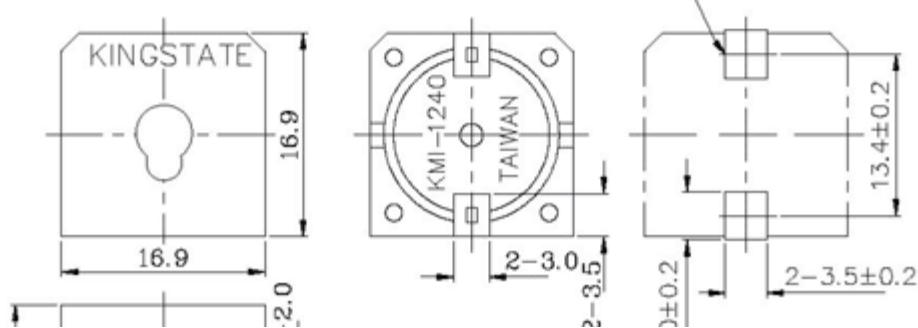

The specification is for reference only. Please confirm the detailed approval sheets before ordering with us.
Kingstate reserves the right to revise or withdraw specifications without advanced notice.