

BWVC00252012R68T00

Search by :

Part Number

Characteristics

Cross reference



MP



Closed Magnetic Circuit Type - Automatic Assembly

Series Pdf



RoHSREACHCoC



ICP Report



Product detail

L(mm) ± 2.5±0.25

W(mm) ± 2.0±0.25

T(mm) ± 1.2±0.05

Inductance(uH) 0.68

Tolerance(±%) 30

Test Frequency 1MHz,200mV

RDC(ohm) 0.035

RDC Tolerance(±%) 30


Isat(A)Typ 2.8

Isat(A)Max 2.52

Irms(A)Typ 2.6

Irms(A)Max 2.34

Operating Temperature −55°C~125°C(Including self - temperature rise)

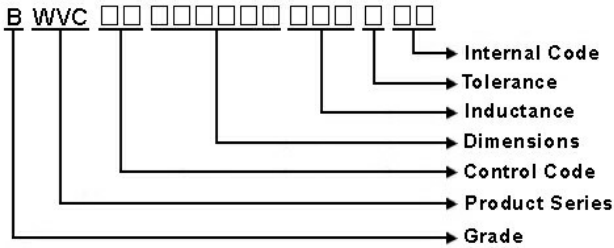

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

[Financial Information](#)

[Corporate governance](#)

[Stakeholder Contacts](#)

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.