


## EMF/ELF Meter

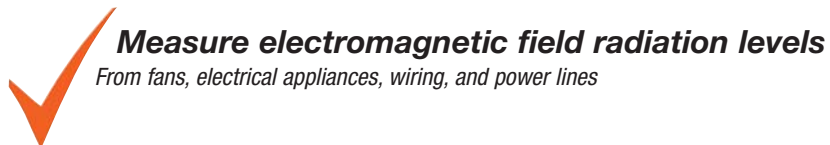

### Measure electromagnetic field radiation levels

*From fans, electrical appliances, wiring, and power lines*

#### Features:

- Large 1 1/2" LCD (1999 count) display of Electromagnetic Field (EMF) level in milliGauss or microTesla
- Accurate measurements to 4% over a measuring range of 0.1 to 199.9mGauss (0.01 to 19.99μTesla)
- ELF frequency bandwidth of 30 to 300Hz  
Single axis - sampling 2.5 times per second
- CE approved, one year warranty
- Dims: 5.2x2.8x1" (132x71x25mm);  
Weight: 6oz (170g)
- Complete with 9V battery



| Specifications      |                                               |
|---------------------|-----------------------------------------------|
| Range               | 0 to 199.9mG (milligauss)<br>0 to 19.99μTesla |
| Frequency Bandwidth | 30 to 300 Hz (ELF frequency range)            |
| Accuracy            | ±(4% + 3digits) at 50-60 Hz                   |
| Number of Axes      | Single axis                                   |

#### Ordering Information:

480823 .....Electromagnetic Field Meter  
409992 .....Soft pouch carrying case

