



Part Number : [1300920104](#)


Product Description : Aero-Motive Slip Ring Component Kit, 30A, 12 AWG, 12 Conductors, Bore Size 22.23mm (.875") Diameter

Series Number : 130092

Status : Active

Product Category : Slip Rings

Engineering Part Number : SR212

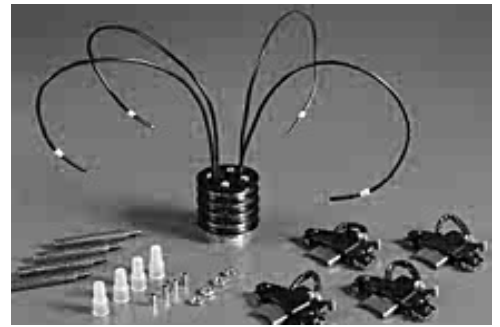

Documents and Resources

Product Environment Compliance

Compliance

| | |
|--------------------|--|
| GADSL/IMDS | Not Relevant |
| China RoHS | Not Reviewed per SJ/T 11365-2006 |
| EU ELV | Not Relevant |
| Low-Halogen Status | Not Reviewed per IEC 61249-2-21 |
| REACH SVHC | Not Reviewed per D(2025)4165-DC (25 June 2025) |
| EU RoHS | Not Reviewed per EU 2015/863 |

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

| | |
|----------------|---|
| Status | Active |
| Category | Slip Rings |
| Series | 130092 |
| Description | Aero-Motive Slip Ring Component Kit, 30A, 12 AWG, 12 Conductors, Bore Size 22.23mm (.875") Diameter |
| Component Type | Component Kit |
| Product Name | Aero-Motive |
| UPC | 78678859307 |

Electrical

| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 30.0A |
| Voltage - Maximum | 600V |

Physical

| | |
|-------------------------------|----------------------|
| Center Bore Diameter | 22.23mm (.875") |
| Mounting Style | Horizontal, Vertical |
| Net Weight | 1.000/g |
| Number of Conductors | 12 |
| Packaging Type | Carton |
| Speed (RPM) | Continuous 125 |
| Temperature Range - Operating | -40° to +120°C |
| Wire Size (AWG) | 14 |