

Eaton STN254033UL50

Catalog Number: STN254033UL50

Eaton TVS diode ESD supp. DFN2510-10L size, 3.3 op. voltage, 0.5 pF, 20 kV, Unidirectional

General specifications

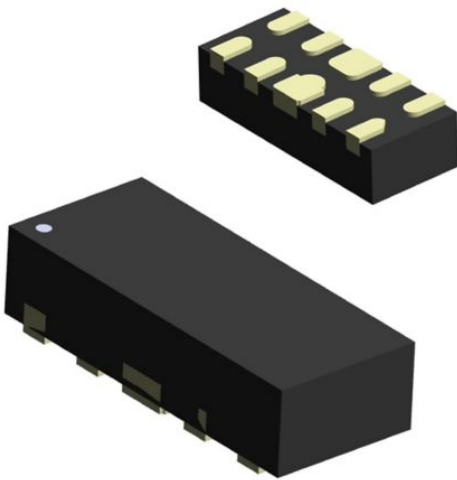


Photo is representative

Product Name	Catalog Number
Eaton TVS diode ESD suppressor	STN254033UL50
UPC	Product Length/Depth
051712771535	2.55 mm
Product Height	Product Width
0.65 mm	1.05 mm
Product Weight	Compliances
0.00365 g	RoHS Compliant

Voltage, current and power ratings

Voltage rating

3.3 V

Clamping voltage

9

Package size, operating temperature, ESD rating

Capacitance

0.5

ESD withstand - air

20

ESD withstand - contact

20

Operating temperature - min

-55 °C

Operating temperature - max

125 °C

Resources

Specifications and datasheets

[Eaton Specification Sheet - STN254033UL50](#)

[Eaton stn254033ul33 and stn254033ul50 TVS diode array ESD suppressor data sheet](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



Eaton.com/socialmedia