



Part Number : [1300940506](#)


Product Description : Bus-Drop Support Grip,
Single Eye, Cable Diameter 13.21-18.54mm
(.520-.730"), Approximate Break Strength 358.34kg
(790 lbs)

Series Number : 130094

Status : Active

Product Category : Cable Grips

Engineering Part Number : 36577

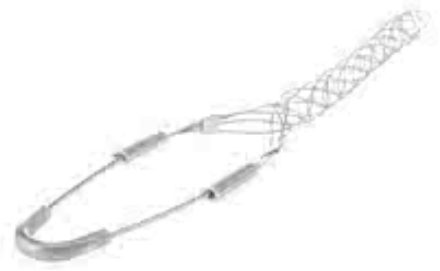


Documents and Resources

Drawings

[PK-130227-004-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Bus-Drop Support Grip, Single Eye, Cable Diameter 13.21-18.54mm (.520-.730"), Approximate Break Strength 358.34kg (790 lbs)
Product Name	Service-Drop
Type	Support Grip
UPC	78678835820

Agency

CSA	LR32159
-----	---------

Physical

Approximate Break Strength	358.34kg (790 lbs)
Bale Length	0.203m (8.00")
Body Style	Straight
Cable Diameter	13.21-18.54mm (.520-.730")
Color - Grommet	N/A
Eye Type	Single
Gender	N/A
Material - Body	N/A
Material - Grip	Galvanized Steel
Mesh Length	0.203m (8.00")
Net Weight	63.842/g
Number of Holes	N/A
O-Ring	N/A

Thread Size	N/A
-------------	-----

This document was generated on Apr 11, 2026