




CT50175M, Cable Tie, 1.75" Max Bundle, 50 Lb Tensile, Natural

By Burndy
Catalog # [CT50175M](#)

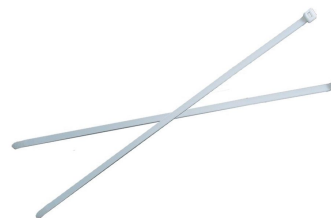

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-1-9
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
Certification - 94V0 Rated	N
UL Listed	No
Certification - UV Rated	No

Dimensions

Package Length	16.500 in
Package Width	11.250 in
Package Weight	2.860 lb.
Dimension - L Length Overall mm	192 mm
Package Height	3.000 in
Width	0.18 in
Dimension - Width inch	0.18 in

Dimension - Width mm	5 mm
Length	8 in
Dimension - Bundle Diameter Max inch	1.875
Dimension - Length Overall inch	7.56 in

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Trade Name	UNIRAP™
Military Specification	MS3367
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
Color	Natural
Type	Standard
UPC 14 Digit GTIN	00781810332559
Material	NYLON 6/6
UPC	781810332559

Logistics

Minimum Pack Quantity	1000
Carton Quantity	10000
Pallet Quantity	99999

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)

