




+ CONNECTORS

RACK & PANEL CONTACTS

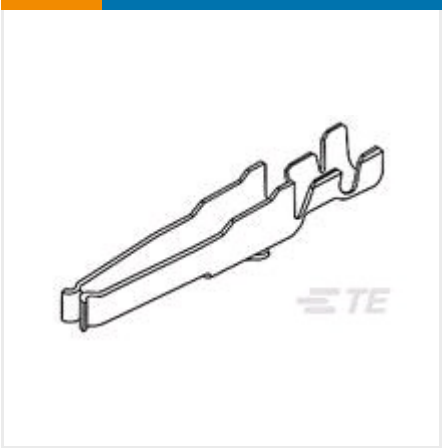

✓ Active

TE CONNECTIVITY (TE)
IEC-F F.CONT.COSI
EUROCARD | Eurocard , IAC

166633-2
TE Internal Number: 166633-2

EU RoHS Compliant
EU ELV Compliant

Contact Type Socket
Contact Configuration Snap-In
Length (mm) 22.2
Contact Mating Area Plating Material Gold
Connector & Contact Terminates To Wire & Cable

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

DOCUMENTATION

Product Drawings

Crimp-On/Snap-In Tab Receptacle Strip
PDF (TIFF AVAILABLE)
English

CAD Files

3D PDF
PDF
3D

Customer View Model
2D_DXF.ZIP
English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

DIN Level II

Connector & Contact Terminates To Wire & Cable

Product Type Contact

Body Features

Body Style Straight

Contact Features

Crimp Type Crimp-On / Snap-In

Contact Angle Straight

Contact Type Socket

Contact Configuration Snap-In

Contact Mating Area Plating Material Gold

Contact Base Material Phosphor Bronze

Contact Mating Area Plating Thickness (µm) .75

Termination Features

Termination Method to Wire/Cable Crimp

Mechanical Attachment

Contact Retention in Housing Crimp Snap-In

Dimensions

Length (mm) 22.2

Wire Range 18 – 16 AWG [.8 mm²]

Wire Insulation Diameter 2 – 2.5 mm [.079 – .098 in]

Operation/Application

For Use With Type F Female Contact

Packaging Features

Packaging Method Loose Piece



Statement of Compliance

Statement of Compliance

PDF

