


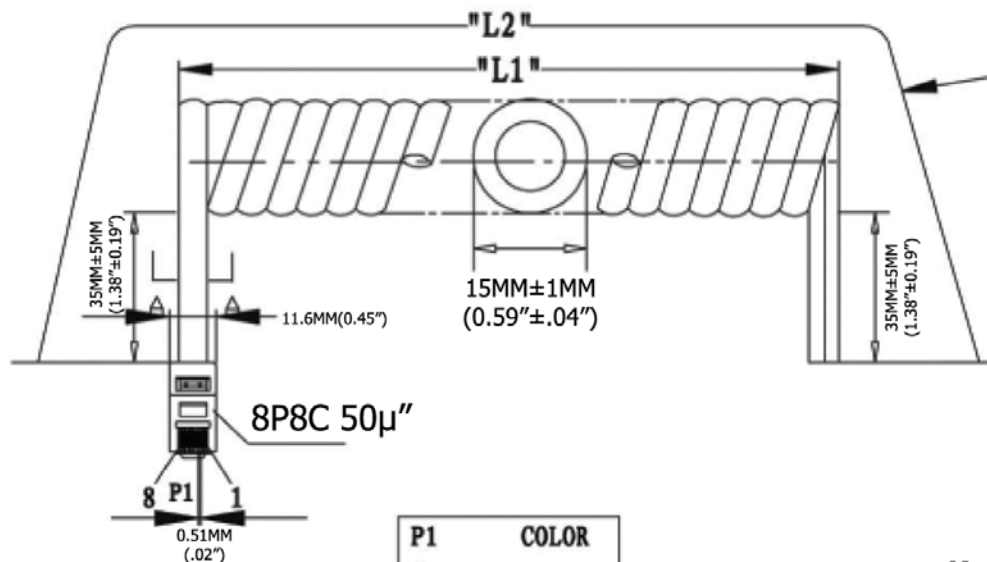

Extended length is with 500g of force

P1	COLOR
1	WHITE
2	ORANGE
3	BLACK
4	RED
5	GREEN
6	YELLOW
7	BLUE
8	BROWN

Extended Length ("L2")	Typical Retracted Length ("L1")
84.0 Inches - 96.6 Inches	39.5 Inches
2,133.6MM-2,453.64MM	1,003.3MM

Material:

- Plug Housing: Polycarbonate, clear
- Plug Terminal: 0.36"[0.14MM] Thick Phosphor Bronze
- Connector: 50μ" of Selective Gold Contact Plating
 - Area, Gold flash over the remainder
 - Over 2.54μm[.000100] thick nickel underplate
- Conductor(X8C): 26AWG (0.12X12) Bare Copper
- Insulation(X8C): PP6331 ID 0.95-1.0
- Jack: PVC No UL 80 P
- Package: Individual PE Bag

Electrical:

- Voltage rating: 30V (DC)

A cross-sectional diagram of a 7-core cable. The diagram shows a central conductor surrounded by insulation, then a jacket, and finally a white layer. The cable is divided into seven segments, each with a different color: Orange, Black, Red, Green, Yellow, Blue, and Brown. The dimensions are given as 8.8MM ± 0.2MM (0.34" ± .008") for the overall diameter and 2.4MM ± 0.2MM (.09" ± .008") for the segment width.

Conductor
Insulation
Jacket
White
Orange
Black
Red
Green
Yellow
Blue
Brown

8.8MM ± 0.2MM
(0.34" ± .008")

2.4MM ± 0.2MM
(.09" ± .008")

SEC: A-A

[illegible]

Item No.	Item Description	Unit	Quantity	Unit Price	Total Price
----------	------------------	------	----------	------------	-------------

AT-C-26-8/8/S-7-OE

Title	NON-UL 26AWG (0.12X12)*8C, O.D.: 2.4*8.8MM, Single Plug, 50μ" of contact plating, SILVER
-------	---

Drawing No.

rev00

Replace

Sheet

RoHS
Complaint

ASSMANN
WSV components