





Perm-O-Pads® Integrated Circuit Mounts

A55485/02-031N PRICE CODE: B
M38527/02-031N

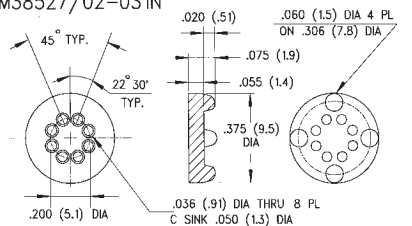


610-075 8 LEADS

PRICE CODE: B

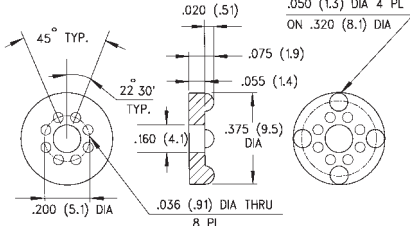


615-075 8 LEADS

A55485/02-033N PRICE CODE: B
M38527/02-033N

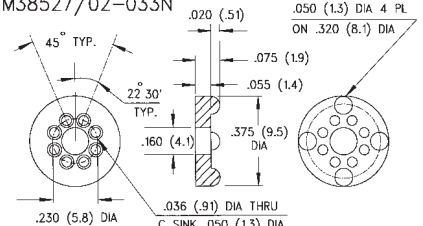

617-075 8 LEADS


PRICE CODE: B

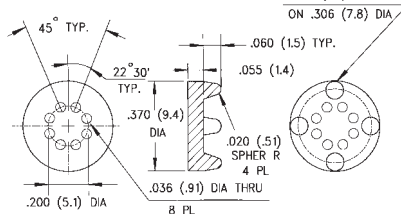

603-115 8 LEADS


**ONLY THE FINEST
U.L. RATED MATERIALS
ARE USED**
PRECISION MOLDED

A55485/02-030N PRICE CODE: B
M38527/02-030N

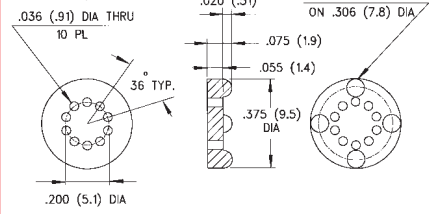

611-075 10 LEADS


PRICE CODE: B

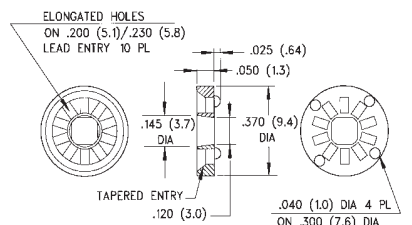

606-075 COLOR: RED 10 LEADS




PRICE CODE: B

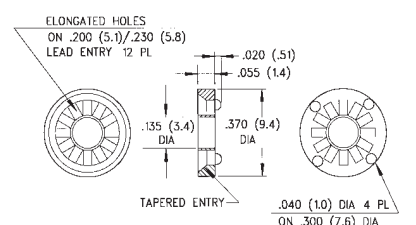

607-075 12 LEADS


.300 (.76) DIA EXIT PRICE CODE: C

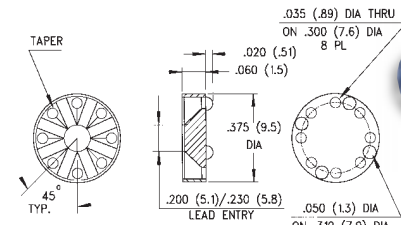

711-085 8 LEADS


VISIT US ON-LINE!
www.bivar.com

A55485/04-013N PRICE CODE: C
M38527/04-013N

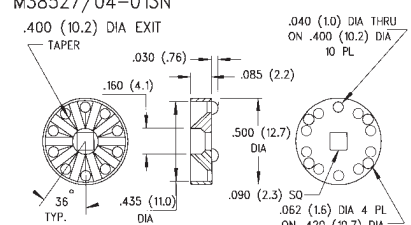


701-130 COLOR: RED 10 LEADS

PRICE CODE: B

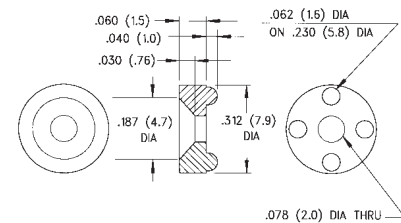


400-100

A55485/07-007N PRICE CODE: A
M38527/07-007N

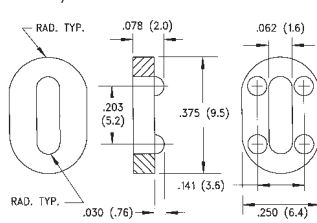

420-078

PRICE CODE: C

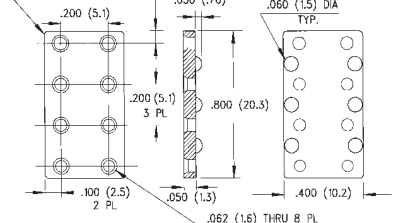

408-080

Material Specifications:

White or Natural Nylon, per ASTM D 4066 PA111, U.L. Rated 94V-2

Oxygen Rating Index: Over 28%

Standard Drawing Tolerances, unless otherwise indicated:

Fractions: = $\pm 1/64$ (.40) .X = $\pm 1/64$ (.40) .XX = $\pm .010$ (.254) .XXX = $\pm .005$ (.127)

