
[Home](#) > [Product Information](#) > [Product List](#)

Product Information >

- Electrical Terminals >
- Lighting system
- Charging Connectors for Electric Vehicles
- Automotive Connectors >
- Nylon Cable Ties
- Green Energy Connector

● Product List

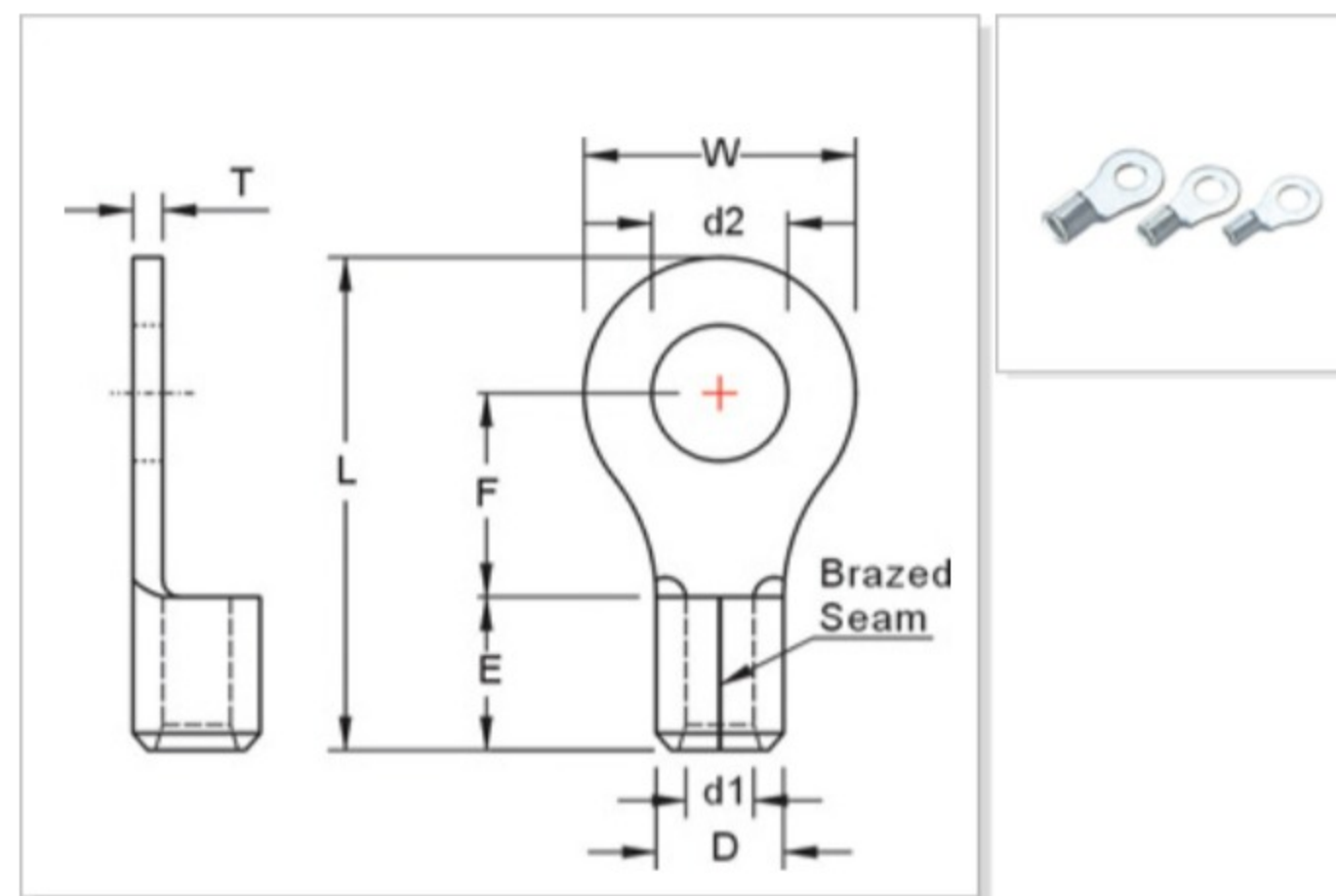

Please access eDM for the latest specifications

MAXIMUM ELECTRIC CURRENT:

A.W.G.	22	20	18	16	14	12	10	8	6	4	2	1/0	2/0	3/0	4/0	250	300	350	400	500	600
AMP.	9	12	17	18	30	35	50	70	95	125	170	230	265	310	360	405	445	505	545	620	690

TERMINAL MATERIAL: COPPER

Product List (Total: 1 records)

Data Source Page NO. : [P.33](#),

WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION inch(mm)							Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	2 x d2		W	F	L	E	D	d1	T	
2 A.W.G. 38 mm ²	<input type="checkbox"/> RNB38-5	<input type="checkbox"/>	#10	0.209 5.3	0.602 15.3	0.685 17.4	1.535 39	0.551 14	0.524 13.300	.370 9.4	0.071 1.8	200

Data Source Page NO. : [P.33](#),