



CT50175C, Tie, 1.75" Max Bundle, 50 Lb
Tensile, Natural

By Burndy
Catalog # [CT50175C](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength, Natural,
Nylon 6/6, 8" Long, 100 pack

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application


For General Purpose

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-1-9
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - UV Rated	No
UL Listed	Yes
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.800 in
Package Weight	0.300 lb.
Package Length	12.000 in
Package Width	5.900 in
Dimension - L Length Overall mm	192 mm
Length	8 in
Dimension - Width mm	5 mm

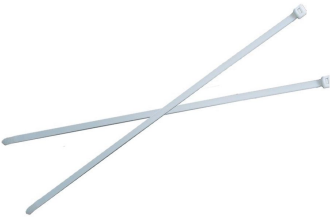

Dimension - Width inch	0.18 in
Dimension - Length Overall inch	7.56 in
Dimension - Bundle Diameter Max inch	1.87 in

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Trade Name	UNIRAP™
Tool Type	Standard
Military Specification	MS3367
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810332443
Type	Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332443

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	10000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)